






European P.C.B. type terminal blocks / EK series

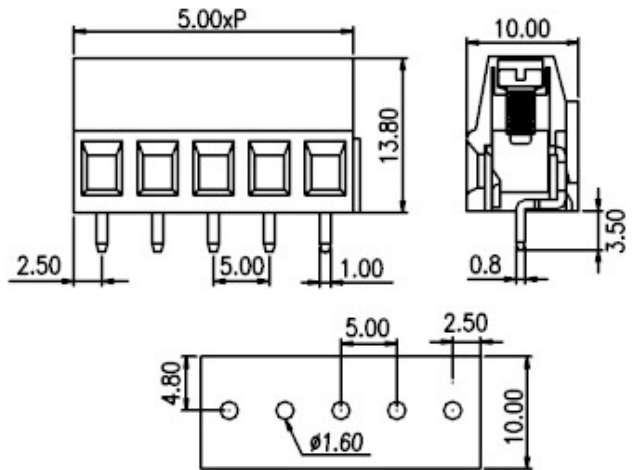

**EK500V**

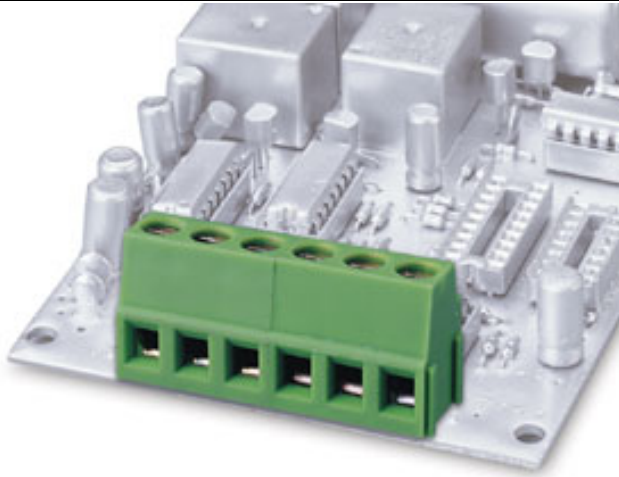

**Pitch: 5.00mm**

|                                      |   |      |
|--------------------------------------|---|------|
| Approval                             |    |      |
| Technical Data                       | UL  | IEC  |
| Rated voltage                        | 300V  | 250V |
| Rated current                        | 20A   | 24A  |
| Wire range                           | 2.5mm <sup>2</sup>  |      |
| Solid wire (AWG)                     | 24~12   |      |
| Stranded wire (AWG/mm <sup>2</sup> ) | 24~12   |      |
| Rated surge voltage (UL/IEC/Max.)    | 1.6 / 2 / 3 KV  |      |
| Torque (Lb-in)                       | 4.4   |      |
| Screw                                | M2.5  |      |
| Wire strip length                    | 6~7mm   |      |
| Pole                                 | Cat. No.  |      |
| 02                                   | EK500V-02P  |      |
| 03                                   | EK500V-03P  |      |

TEL: +886-2-2908-0614

FAX: +886-2-2908-8549

E-mail: [infor@dinkle.com.tw](mailto:infor@dinkle.com.tw)