


R13-502

Screw Type

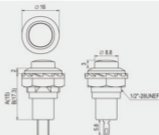

Rating

3A 125V AC
1.5A 250V AC

Contact resistance

50mΩ Max

Insulation resistance

DC 500V 100MΩ Min

Dielectric strength

AC 1000V 1 minute

Cut-out



±0.3 3 mm max

FEATURES

- * MATERIAL: Actuator and Frame are nylon (UL flame: 94V-2). Terminals are silver plated brass. Base is PBT.
- * M types are metal frames, nickel plated brass.
- * Mounted by nut.

R13-502

BODY

Plastic Body



Metal Body



FUNCTION



(Only for R13-502MC)

* () =momentary

TERMINAL

0 5 SO

