


# ED 130

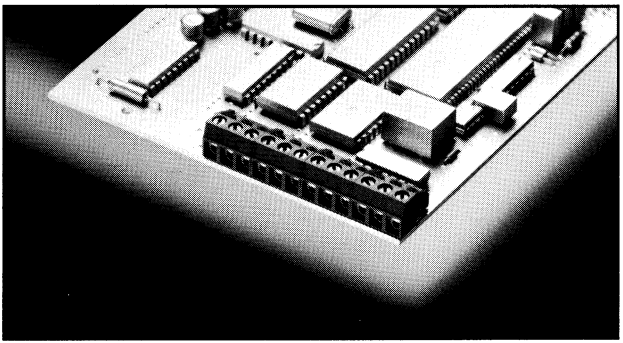

Spacing 5.0 mm  
insert required no. of poles \*\*  
How to order see page 6

## Ratings:



UL1059



CSA 22.2 No. 158



DIN VDE 0627

<b>Rated Voltage</b>	<b>250 VB</b>	<b>150 VB</b>	<b>250 V</b>
<b>Rated Current</b>	<b>10 A</b>	<b>7 A</b>	<b>10 A (T60)</b>
<b>Wire Size</b>	<b>AWG 22-14</b>	<b>AWG 22-18</b>	<b>1.5 mm<sup>2</sup></b>
<b>Test Voltage</b>			<b>2.21 kV</b>
<b>Rated Torque/Screw Size</b>			<b>0.4 Nm/M2.6</b>

## Rated Cross Section

Single Wire (solid)	1.5 mm <sup>2</sup>
Stranded Wire (flexible)	1.0 mm <sup>2</sup>
Stranded wire with Ferrules	1.0 mm <sup>2</sup>

## Dimensions

Spacing	5.0 mm
Stripped Length	6.0 mm

## Materials

Insulating Material	PA
Flammability Class	UL94 V-0
Temperature Range	-30°C/+105°C
Terminal Block	CuZn
Contact	CuBe
Color	Blue

