



APPLICATION

PN# 173243

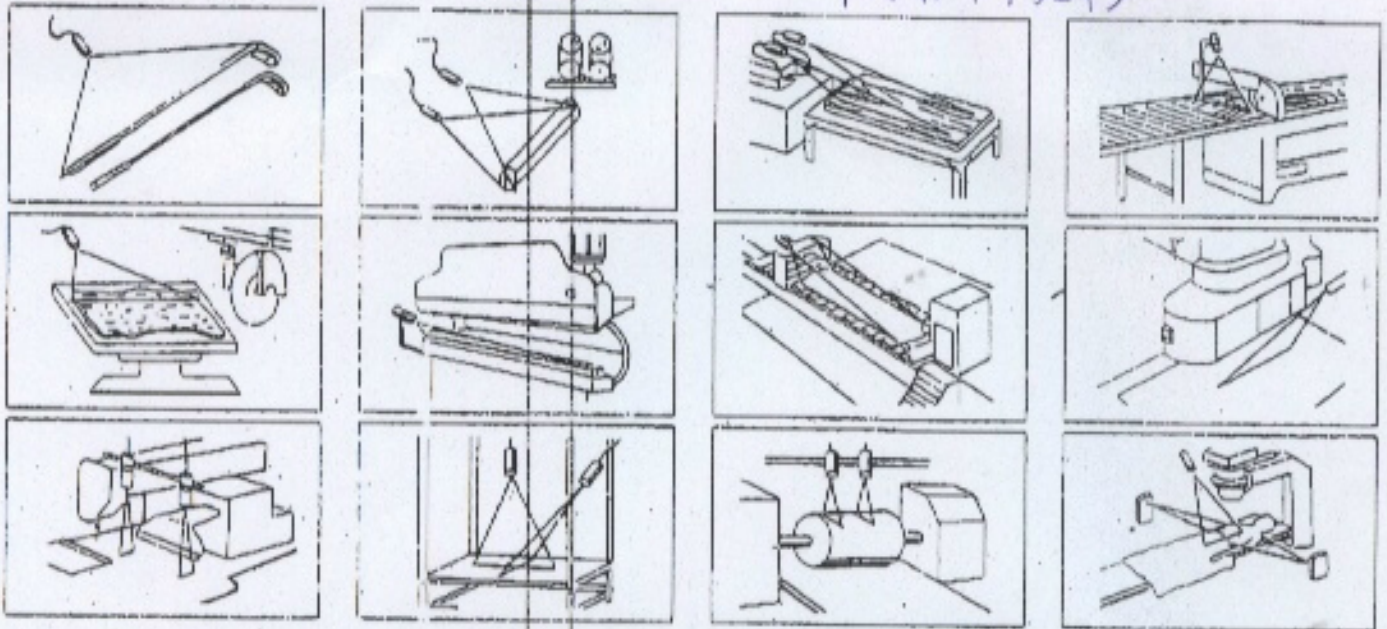


DIODE LASER

- APC power control
- Current stable control
- Operate Voltage: 3V-5V
- Focus Adjustable

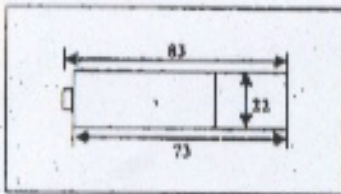


Example: 650nm/10mW/Line

UM650-10-G

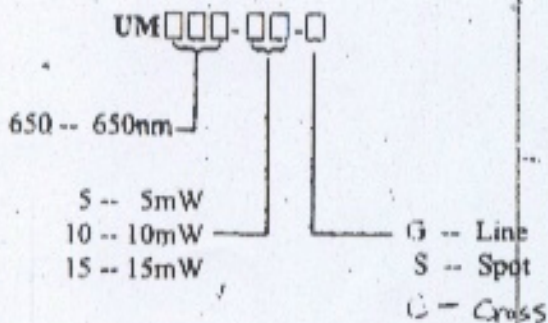


POWER SUPPLY

- Constant voltage, low ripple.
- Short circuit protection.
- Current limit protection: 100mA
- AC95V-AC125 or AC190V-AC250V switchable.

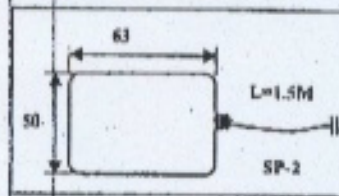


SP-2

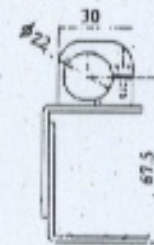

LASER HOLDER

- X-Y-TILT-θ movement

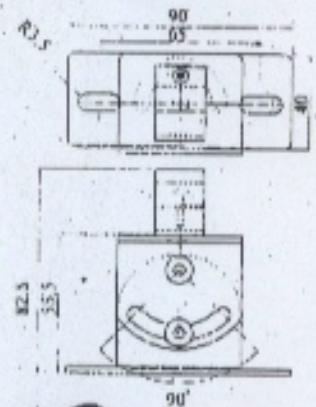

08UMM-A

