

Piezoelectric Sound Components > Piezoelectric Sounders > External-Drive



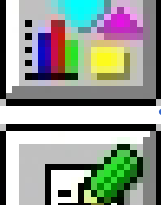







How to check EU RoHS Compliant of Our Products is [here](#).

Product Lifecycle Stage	in Production
Recommended Rank	Preferred

Specification

Global Part Number	PKM22EPPH2002-B0
Previous Part Number	
Sound Pressure Level	70dB min.
Measure Condition of Sound Pressure Level	[3Vp-p,2kHz,square wave,10cm]
Oscillating Frequency	
Measure Condition of Oscillation Frequency	
Current Consumption	
Measure Condition of Current Consumption	
Min. of Operating Voltage Range	
Max. of Operating Voltage Range	25.0 Vp-p max.
Capacitance	19.0nF ±30%
Measure Condition of Capacitance	[120Hz]
Type	Pin Type
Operating Temperature Range	-20 to +70°C
Storage Temperature Range	-30 to +80°C

Details

- ?  [Part Numbering](#)
- ?  [Appearance](#)
- ?  [Dimensions](#)
- ?  [Features and Applications](#)
- ?  [Frequency Response](#)
- ?  [Frequency Response](#)
- ?  [Recommended Circuit](#)
- ?  [Notice \(storage and operating condition\)](#)
- ?  [Notice \(soldering and mounting\)](#)
- ?  [Notice \(handling\)](#)

Minimum Quantity

180mm Paper Tape	
180mm Embossed Tape	
330mm Paper Tape	
330mm Embossed Tape	
Bulk Case	
Bulk(Bag)	
Ammo Pack	
320Reel	
Magazine	
Box	750

Please approve our product specifications or to transact the approval sheet for product specifications before ordering. Please read rating and !Cautions first.
 Product specifications in this catalog are as of January 2008.

All products and company names herein are trademarks or registered trademarks of their respective owners.