


NCM15X7R103K50TRF

Ceramic Capacitor, Radial, 0.01 uF, 10% Tol, 50V,
 0.1" Lead Spacing

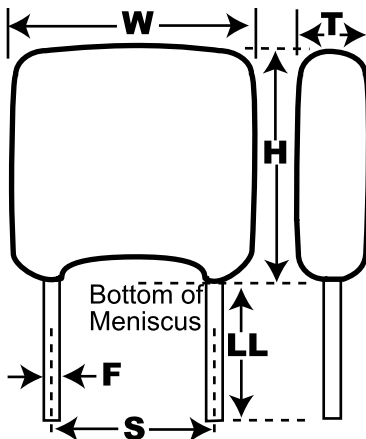

Dimensional Data (in)

Specifications

ID	Dimensions	Tolerance	Specifications
W:	0.15	max	Capacitance: 0.01 uF
H:	0.21	max	Tolerance: 10%
T:	0.1	max	Voltage: 50V
S:	0.1	+/-0.03	Temperature Coefficient: X7R
LL:	1.25	min	Body Type: Conformal
F:	0.02	Nom	Lead Spacing: 0.1"
			Lead Form: Straight Leads
			Lead Type: Standard Leads
			Packaging: T&R, Type 1, (H0=16mm)
			Package Quantity: 3500

