


Distributed by:




[www.Jameco.com](http://www.Jameco.com) ♦ 1-800-831-4242

The content and copyrights of the attached material are the property of its owner.


# QJT-360S QJT-365S

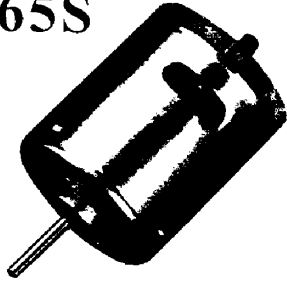

DIRECTION OF ROTATION

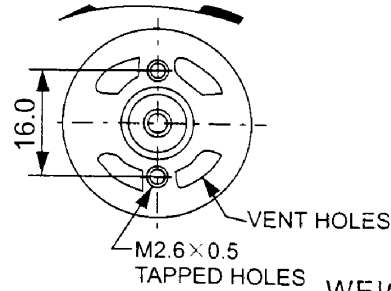

WEIGHT: 42g (APPROX)

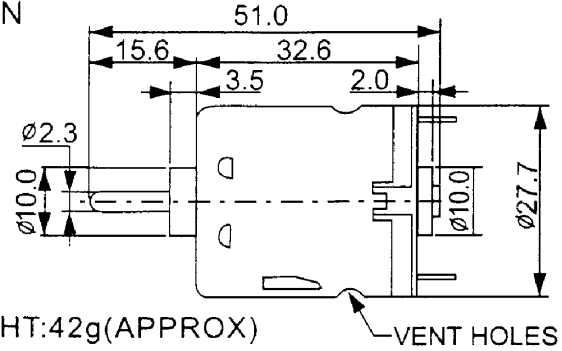

Jameco Part Number  
206949

MODEL	VOLTAGE		NO LOAD		AT MAXIMUM EFFICIENCY					STALL TORQUE	
	OPERATING RANGE	RATED	SPEED	CURRENT	SPEED	CURRENT	TORQUE		POWER	STALL TORQUE	
	V	V	rpm	A	rpm	A	g.cm	mN.m	W	mN.m	g.cm
QJT-360-10500	12.0 ~ 30.0	24.0	9300	0.06	7310	0.22	34.0	3.33	2.57	15.7	160
QJT-360-24110	4.5 ~ 12.0	6.0	10600	0.27	8400	1.03	36.5	3.58	3.14	17.3	176
		9.0	16000	0.28	13140	1.28	46.5	4.56	6.28	25.6	261
QJT-360S-14280	9.0 ~ 30.0	12.0	6200	0.09	4930	0.35	44.5	4.36	2.20	20.8	212
QJT-360S-14280	9.0 ~ 30.0	24.0	12560	0.10	10470	0.50	61.5	6.03	6.60	36.3	370
QJT-365S-10200	12.0 ~ 28.0	18.0	8100	0.07	6150	0.22	32.2	3.16	2.0	13.1	134
		24.0	11000	0.08	8650	0.28	42.3	4.15	3.7	18.8	192
QJT-365S-12180	6.0 ~ 30.0	12.0	5800	0.08	4340	0.24	32.7	3.21	1.5	12.7	130
QJT-365S-14140	6.0 ~ 26.0	12.0	7700	0.11	5660	0.40	43.5	4.26	2.5	16.1	164