



SPECIFICATIONS SHEET

PRODUCT TYPE : PIEZO BUZZER

PRODUCT SERIES : SL15

DESCRIPTION : PZ BUZZER SIREN 12VDC L/W ABS SP RoHS

COLOR : BLACK

ELECTRICAL SPECIFICATIONS


MODEL NO.	<i>SL15R3120LF - LA</i>	
OPERATING VOLTAGE RANGE	(VDC)	6.0 ~ 16.0
RATED VOLTAGE	(VDC)	12.0
* MAX. RATED CURRENT	(mA)	250.0
* MIN. SOUND OUTPUT	(dBA/ 30 cm)	105.0
* FREQUENCY	(Hz)	1500 ~ 3500
TONE NATURE		SIREN
OPERATING TEMPERATURE	(°C)	- 20 ~ + 60
TERMINAL		LEADWIRE (UL1007 , AWG#22)
HOUSING MATERIAL		ABS
WEIGHT	(g)	75.0

* Value applying at rated voltage


DIMENSIONS

UNIT : mm

TOP VIEW

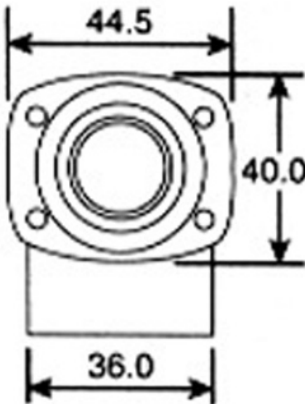

SIDE VIEW

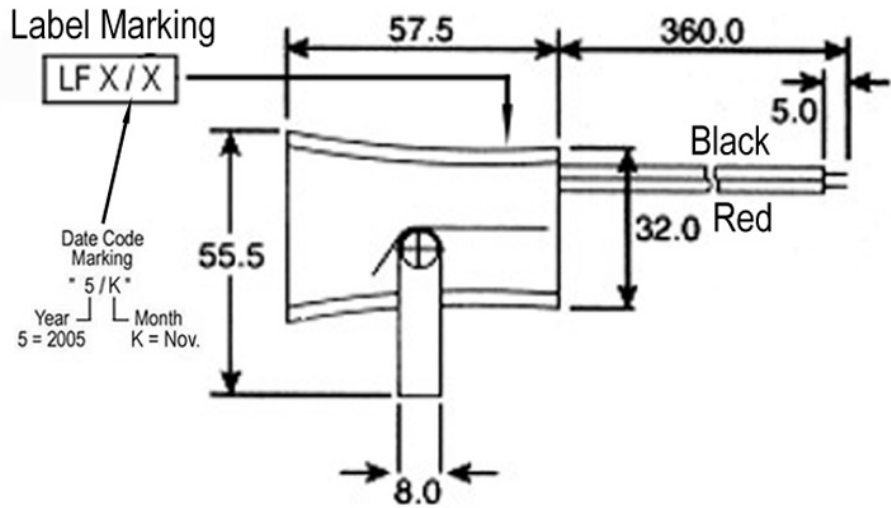

Approved By :
Date : 4-Nov.-2005

Prepared By :
Date : 4-Nov.-2005

Modify :	Date :	By :