





VOLEX

GROUP

### Standard Cord Details: 17002A 10 B1



Specifications	
Certifications	
Part Number	17002A 10 B1
Connector Type	C13
Plug Type	5-15P
Category	Plastic
Application	Detachable
Plug Catalog No.	US15S3
Connector Catalog No.	386A
Cable	SVT AWG 18x3
Jacket Color	Black
Length in Feet	1.5
Length in Meters	.46
Temperature Rating	60C
Packaging Units Per Carton	50
Color Coding	North America
Nominal OD in Inches	0.246
Nominal OD in Millimeters	6.25
Notes	See similar item 17000A for 36" version.

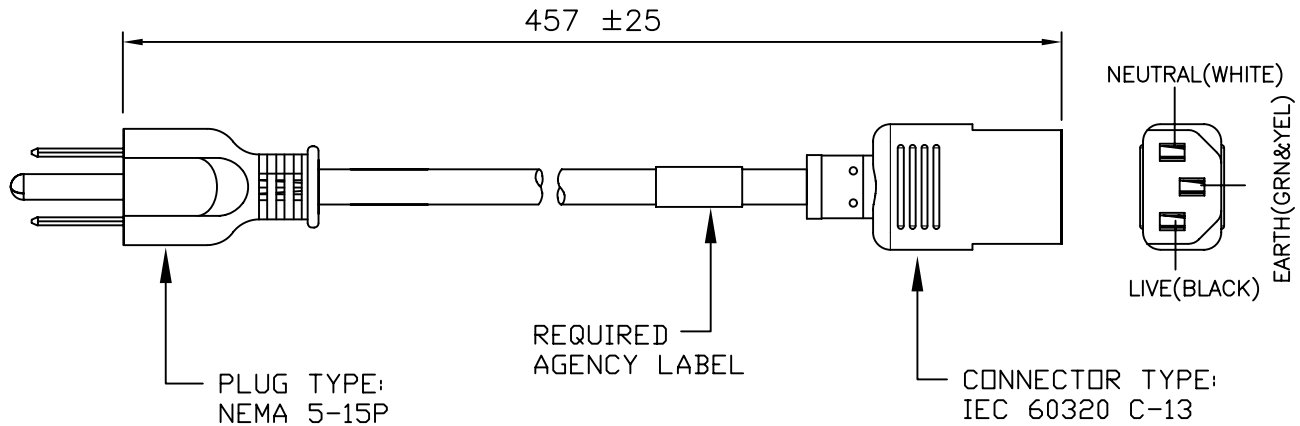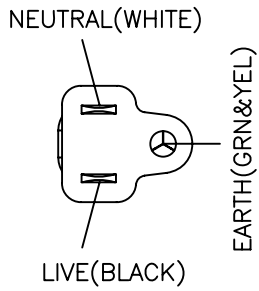

VOLEX RESERVES THE RIGHT TO ALTER NON-CRITICAL DIMENSIONS WITHOUT NOTICE.

PACKAGING: BULK PUT-UP (NO FOLD & TIE OR COIL)

- NOTES:**
- 1) CORDAGE: 18/3 SVT, 60°C, BLACK
  - 2) APPROVALS:
  - 3) RATING: 10 AMP/125 VOLTS
  - 4) FLAME RATING : FT2
  - 5) PACKAGING: 25 PIECES/CARTON
  - 6) ALL DIMENSIONS IN MILLIMETERS.

3	REVISED TO SHOW CHINA MANUFACTURED CORD	11/26/07
2	FORMAT UPDATE	08/20/04
1	C.U.D - NEW RELEASE	06/11/04
REV	DESCRIPTION	DATE

	<input checked="" type="checkbox"/> Indianapolis, IN <input type="checkbox"/> Conover, N.C. <input type="checkbox"/> Freemont, CA <input type="checkbox"/> Aguascalientes, MX <input type="checkbox"/> Tijuana, Mexico <input type="checkbox"/> Hermosillo, MX <input type="checkbox"/> Clinton, AR <input type="checkbox"/> Kanata, Canada	<b>Proprietary Notice:</b> This document is the property of Volex Incorporated. The information contained herein is not to be disclosed to anyone without the express written consent of Volex Inc.	<b>MATERIAL:</b> PLUG: PVC, BLACK JACKET: PVC, BLACK	<b>SCALE:</b> NOT TO SCALE	<b>ECD:</b> N/A	<b>ITEM DESCRIPTION</b> CORDSET - NORTH AMERICAN DETACHABLE POWER SUPPLY CORD (1.5')		
	<b>FINISH:</b> JACKET: SMOOTH		<b>TOLERANCE UNLESS OTHERWISE SPECIFIED</b> .XXX ± .005 .XX ± .02 .X ± .03 FRACT. ± 1/32 ANGULAR ± 1/2°		<b>APPROVED</b> STC	<b>DRAWN BY</b> ARK	<b>DATE:</b> 06/11/04	<b>PART NO.</b> 17002A 10 B1