

Distributed by:

**JAMECO**<sup>®</sup>  
ELECTRONICS

**www.Jameco.com ♦ 1-800-831-4242**

The content and copyrights of the attached  
material are the property of its owner.

Jameco Part Number 208857



# PCB TERMINAL BLOCKS

ITEM NO. GGE

APPROVALS:

## 材質及規格處理

本體	PA66 UL94V-0黑
端子	Brass 鍍鎳
螺絲	鐵 鍍鎳

## Materials

Plastic Housing	PA66, UL94V-0, Black
Terminal	Brass, Nickel Plated
Screw	Steel, Nickel Plated



## 材質及規格處理

使用溫度	-40°C ~ +105°C
耐電壓	AC2000V 一分鐘
絕緣阻抗	500MΩ or More at DC 500V
使用線徑	22~12 AWG
最大鎖緊 扭力	10Kg-cm

## Specifications


Working Temperature	-40°C ~ +105°C
Insulation withstand Voltage	AC 2000V at 1 minute
Insul. Resistance	500MΩ or More at DC 500V
Wire Range	22~12 AWG
Max. Torque Value	10kg-cm

## GGE-10 / 600V 10A

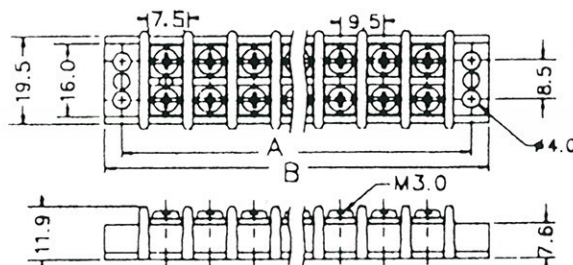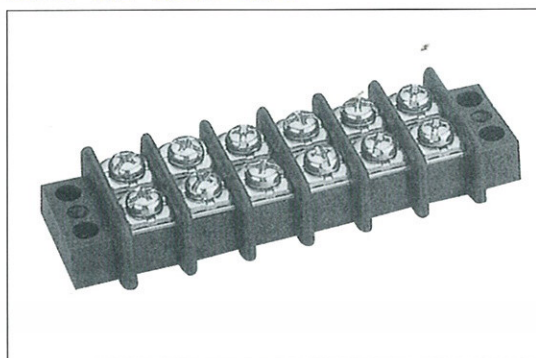



P數	1	2	3	4	5	6	7	8	9	10	11	12	13	14
A	19	28.5	38	47.5	57	64.5	76	85.5	95	104.5	114	123.5	133	142.5
B	26.5	36	45.5	55	64.5	74	83.5	93	102.5	112	121.5	131	140.5	150

## GGE-10Y / 600V 10A

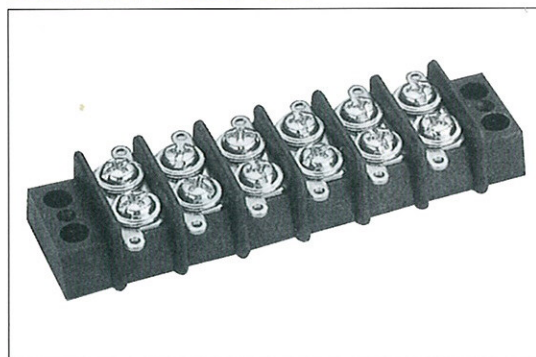

P數	15	16	17	18	19	20	21	22	23	24	25	26	27	28
A	152	161.5	171	180.5	190	199.5	209	218.5	228	237.5	247	256.5	266	275.5
B	159.5	169	178.5	188	197.5	207	216.5	226	235.5	245	254.5	264	273.5	283



### GGE-20 / 600V 20A

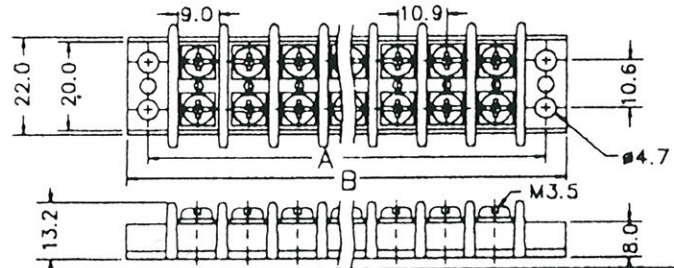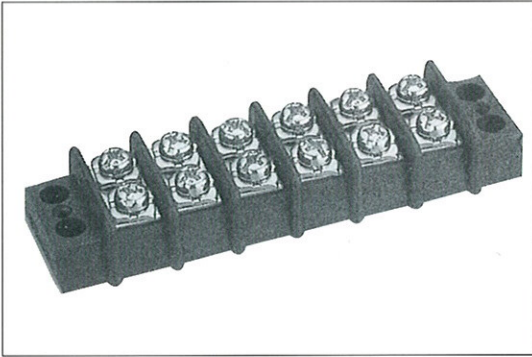

P數	1	2	3	4	5	6	7	8	9	10	11	12	13
A	21.8	32.7	43.6	54.5	65.4	76.3	87.2	98.1	109	119.9	130.8	141.7	152.6
B	30.8	41.7	52.6	63.5	74.4	85.3	96.2	107.1	118	128.9	139.8	150.7	161.6

P數	14	15	16	17	18	19	20	21	22	23	24	25	26
A	163.5	174.4	185.3	196.2	207.1	218	228.9	239.8	250.7	261.6	272.5	283.4	294.3
B	172.5	183.4	194.3	205.2	216.1	227	237.9	248.8	259.7	270.6	281.5	292.4	303.3

### GGE-30 / 600V 30A

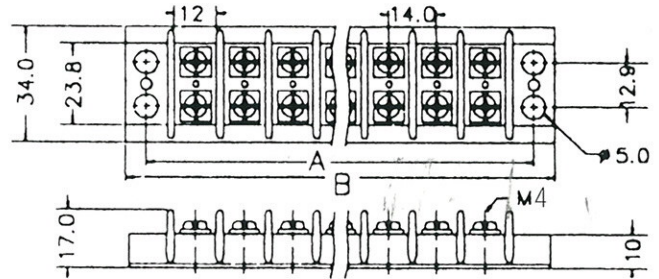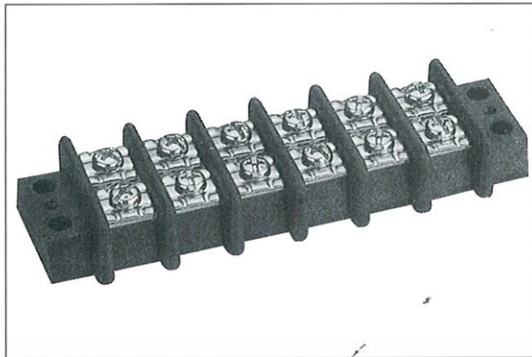

P數	1	2	3	4	5	6	7	8	9	10	11	12
A	28	42	56	70	84	98	112	126	140	154	168	182
B	38	52	66	80	94	108	122	136	150	164	178	192

P數	13	14	15	16	17	18	19	20	21	22	23	24
A	196	210	224	238	252	266	280	294	308	322	336	350
B	206	220	234	248	262	276	290	304	318	332	346	360