

LF-1680 MICRO DIGITAL REWORK STATION




Humanism interface:
The angle of control panel is conform to humanism .It's easy to read and set




Minytype station:
Less desktop occupation



Eligibility fitting combination:
Provides many kinds of for the customer selects the disposition, enable the customer to obtain a more reasonable enhancement in the economic efficiency.

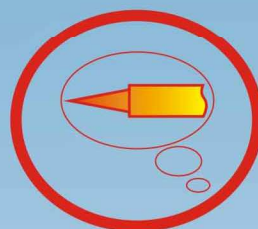

Hi-power heater:
Temperature climbs fast, favored by lead free soldering

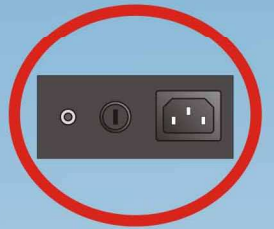

Build-up grounding:
Can link up ESD wrist strap

Product Features:

Password lock: Convenient for control

Minytype station: Less desktop occupation

°C / °F Select Mode: May set display °C / °F

Real-temp modification: Real temperature can modify Manually

TWZ/SIA Dual Mode: Switch the function quickly that you want to select

Sensor fail notification: When the sensor failed, "S-E" will Be shown, SIA will power off

Heater fail notification: When the heater failed, "H-E" will Be shown, SIA will power off

SIA Heating curve determination:



SPECIFICATION:

Input power	100-120Vac 60Hz	
	220-240Vac 50Hz	
Wattage	SIA	80W
	TWZ	80W
Temperature range	SIA	200-480°C
	TWZ	200-450°C
Standard tip	SIA	44-510601
	TWZ	46-060102



XYTRONIC CO.,LTD
<http://www.xytronic.com>