


# Accessories



## EMI & PFC Filter

### Instruction

PLF-2000 series are developed on the basis of environment protection. It can efficiently solve EMC & harmonic current problems caused by electronic products. With PLF-2000, your products will meet harmonic current regulation (IEC1000-3-2/ EN61000-3-2) and also improve immunity (IEC1000-4/ EN61000-4) EMI conduction (EN55022/ EN55011) greatly.


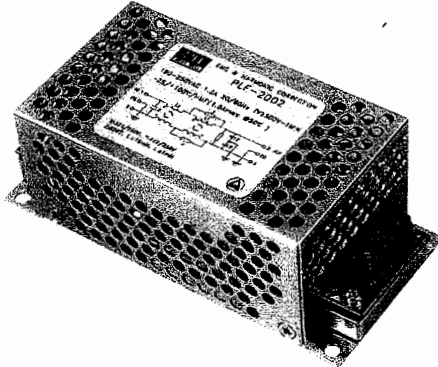


132x 60x 46 mm

- Max. input power..... 200W
- Attenuation.....-20dB(frequency: 0.15~30MHz, measurement condition: CISPR PUB. 17, 50W/ 50W)
- Operating temperature.....-25°C~85°C(derating output at 2.5% per degree from 50°C~85°C)
- Operating humidity..... 30~95%RH (non condensing)
- Withstand voltage..... 1500VAC 1min. (input & output-FG)
- Safety standard..... TUV EN133200
- Harmonic corrector..... Meet IEC1000-3-2 (EN61000-3-2)
- Weight..... 550g

### Characteristic of harmonic corrector

(Test conditions:  $V_{in}=230VAC$ ,  $W_{in}=200W$ ,  $T_a=25^{\circ}C$ )

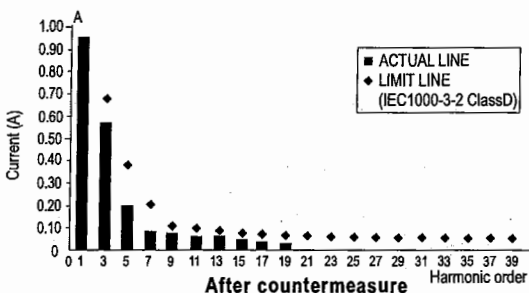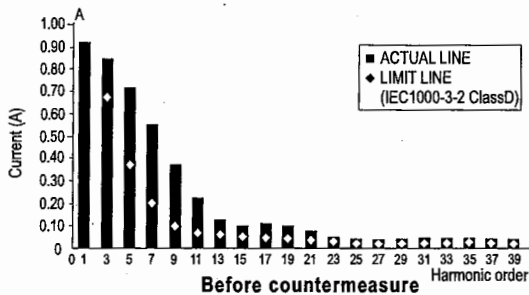

Stock No.	Type No.	Input Voltage	Rated Current	Leakage Current
-----------	----------	---------------	---------------	-----------------

## Power Cord

	<ul style="list-style-type: none"> <li>• Stock No.: 61001</li> <li>• Type No.: YP-12+YC-12</li> <li>• American plug</li> <li>• Rating: 125VAC@10A</li> <li>• Cord.: SVT, 18AWGx3C</li> <li>• Color: black</li> <li>• Length: 6 feet</li> <li>• Withstand: 2500VAC@1S</li> <li>• Safety: UL, CSA</li> </ul>
	<ul style="list-style-type: none"> <li>• Stock No.: 61003</li> <li>• Type No.: YP-35+YC-12</li> <li>• Australian plug</li> <li>• Rating: 250VAC@10A</li> <li>• Cord.: H05VVF, 0.75mm<sup>2</sup>x3G</li> <li>• Color: black</li> <li>• Length: 6 feet</li> <li>• Withstand: 2500VAC@1S</li> <li>• Safety: SAA</li> </ul>
	<ul style="list-style-type: none"> <li>• Stock No.: 61004</li> <li>• Type No.: YP-22+YC-12</li> <li>• Euro plug</li> <li>• Rating: 250VAC@10A</li> <li>• Cord.: H05VVF, 0.75mm<sup>2</sup>x3G</li> <li>• Color: black</li> <li>• Length: 6 feet</li> <li>• Withstand: 2500VAC@1S</li> <li>• Safety: VDE, D, ND, S, FI, QVE, CEBC, KEMA</li> </ul>
	<ul style="list-style-type: none"> <li>• Type No.: YP-21+YC-13</li> <li>• Euro plug</li> <li>• Rating: 250VAC@2.5A</li> <li>• Cord.: H03VVH2-F, 0.75mm<sup>2</sup>x3G</li> <li>• Color: black</li> <li>• Length: 6 feet</li> <li>• Withstand: 2500VAC@1S</li> <li>• Safety: VDE, D, ND, S, FI, QVE, CEBC, KEMA</li> </ul>
	<ul style="list-style-type: none"> <li>• Type No.: YP-60+YC-12</li> <li>• UK plug</li> <li>• Rating: 250VAC@10A</li> <li>• Cord.: H05VV-F, 0.75mm<sup>2</sup>x3G</li> <li>• Fuse: 250VAC@13A</li> <li>• Color: black</li> <li>• Length: 6 feet</li> <li>• Withstand: 2000VAC@15M</li> <li>• Safety: BS 1363</li> </ul>



### Best Products also need Best services.

We have authorized distributors all over the world. They have sufficient stock for your prompt delivery. Also they can offer you technical support & RMA services.