



SPECIFICATIONS SHEET

PRODUCT TYPE : MECHANICAL BUZZER

PRODUCT SERIES : DB-E208

DESCRIPTION : MC BUZZER SINGLE 6VDC L/W ABS SP RoHS

COLOR : BLACK

ELECTRICAL SPECIFICATIONS


MODEL NO.		20S1060LF - LA
OPERATING VOLTAGE RANGE	(VDC)	4.0 ~ 8.0
RATED VOLTAGE	(VDC)	6.0
* MAX. RATED CURRENT	(mA)	25.0
* MIN. SOUND OUTPUT	(dBA/ 20 cm)	75.0
* FREQUENCY	(Hz)	400 +/- 100
TONE NATURE		SINGLE
OPERATING TEMPERATURE	(° C)	-10 ~ +60
TERMINAL		LEADWIRE (UL1095 , AWG#26)
HOUSING MATERIAL		ABS
WEIGHT	(g)	10.0

* Value applying at rated voltage


DIMENSIONS


UNIT : mm

TOP VIEW

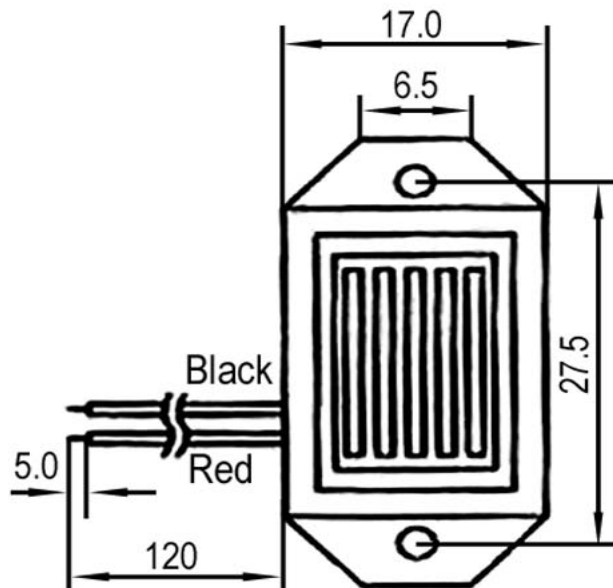

SIDE VIEW

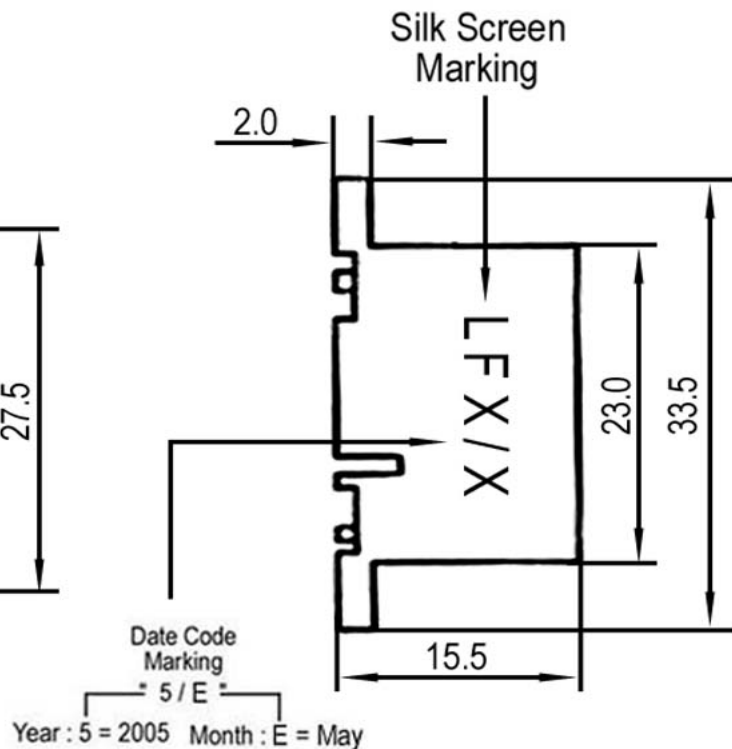

Approved By : 
Date : 25-May-2005



Prepared By :
Date : 25-May-2005





Modify :



Date :	By :