



## Specifications Sheet

Product Type : ***Mechanical Buzzer***

Product Series : ***DB-E208***

Description : ***MC BUZZER SINGLE 6VDC LW ABS RoHS***

Color : ***Black***

### ***Electrical Specifications***


<b>Model No.</b>	<b>20S1060LFLA</b>	
Operating Voltage Range ( VDC )	4.0 ~ 8.0	
Rated Voltage ( VDC )	6.0	
* Max. Rated Current ( mA )	25.0	
* Min. Sound Output ( dBA/ 20.0 cm )	75.0	
* Frequency ( Hz )	400.0 ± 100.0	
Tone Nature	Single	
Operating Temperature ( ° C )	- 20.0 ~ + 60.0	
Storage Temperature ( ° C )	- 30.0 ~ + 70.0	
Terminal	Leadwire ( UL1095 , AWG#26 )	
Housing Material	ABS	
Weight ( g )	10.0	

\* Value applying at rated voltage

### **Dimensions**

Unit : **mm**

Tolerance : **± 0.5 mm**

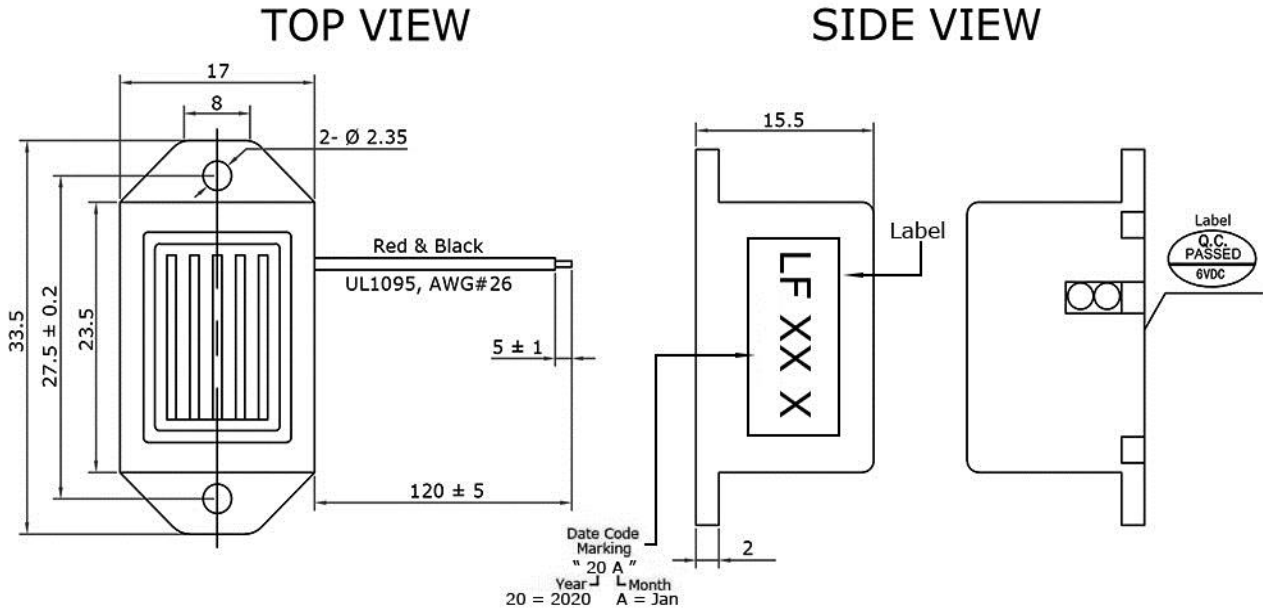

Approved By :   
Date : 02 Jan 2020

Prepared By :   
Date : 02 Jan 2020

Modify :	Date :	By :