

Prototype circuit board for general purpose analog and digital use.

Features


- *ProtoBoard* saves time! ProtoBoard-2H has a general purpose stripboard circuit pattern that is pre-cut with 2 holes per segment.
- 0.1" hole spacing for DIP integrated circuits and headers.
- BusBoard Size1 is $\frac{1}{4}$ the size of a standard 3U size VME board.
- Four mounting holes provided.

Specifications

- Etched FR4 glass-epoxy circuit board.
- Single sided, 1oz/ft² copper with an anti-tarnish coating for easy soldering. Lead free and RoHS compatible..
- Holes are drilled on 0.1" (2.54mm) centers.
- 0.037" (0.94mm) holes sized for ICs or square post headers.
- 31 x 19 holes. Four 0.125" mounting holes.
- Size 1 = 50 x 80mm (1.97 x 3.15in), 1/16" thick (1.6mm)

Order Part# PR2H1

PR2H1 Board Layout (actual size)

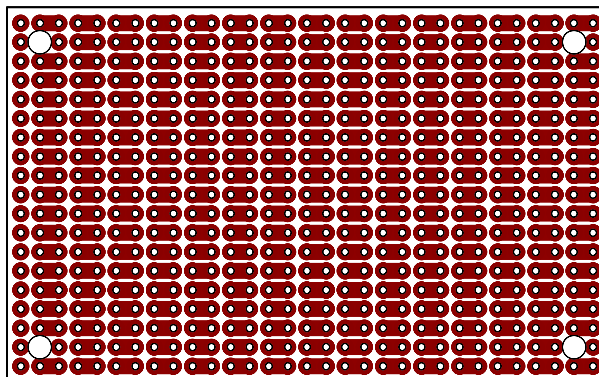

PR2H1 Board Photo



Board Dimensions

