



# Mechanical Buzzer

2192472

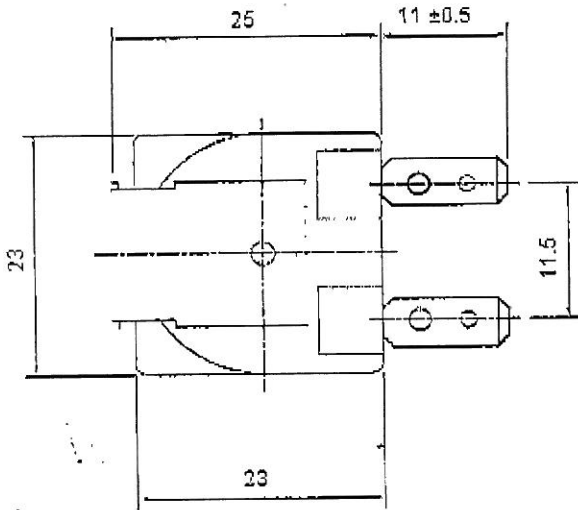

Dimensions : Millimetres

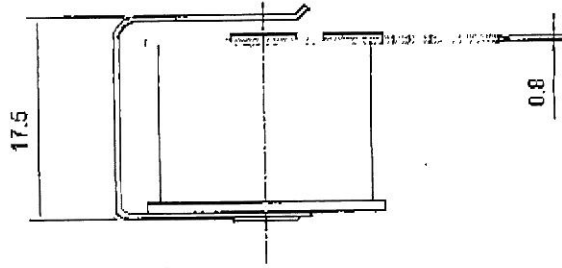

RoHS  
Compliant

## Specifications:

Rated voltage	: 120 VAC / 50 to 60 Hz
Maximum rated current	: 180 mA
Coil resistance	: 100 $\Omega$ $\pm$ 10%
Minimum sound pressure level	: 75 dB at 24 V ac / 20 cm
Case material / colour	: Null
Operating temperature	: -25 to +75°C
Store temperature	: -30 to +60°C
Weight	: 26 g

1-1

1

2