


Mechanical Buzzer

2192499

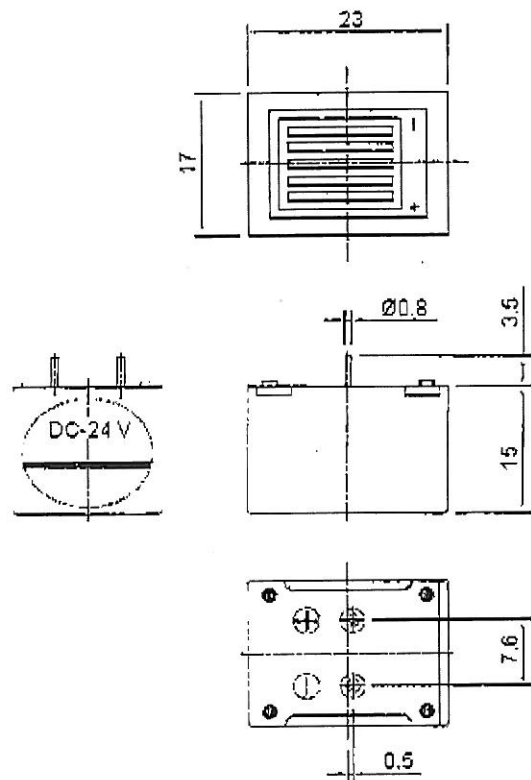

Dimensions : Millimetres

Specifications:

Rated Voltage	: 24 V dc
Operating Voltage	: 15 to 27 V dc
Maximum Rated Current	: 30 mA / 24 V dc
Minimum Sound Pressure Level	: 75 dB / 20 cm
Resonant Frequency	: 400 ±100 Hz
Response Time	: 50 ms
Case Material / Colour	: ABS / Black
Operating Temperature	: -20°C to +60°C
Storage Temperature	: -30°C to +70°C
Weight	: 10 g