


OD9225 Series



DC Fan - 5, 12, 24, 48V
92x25 (3.62"x 1.00")

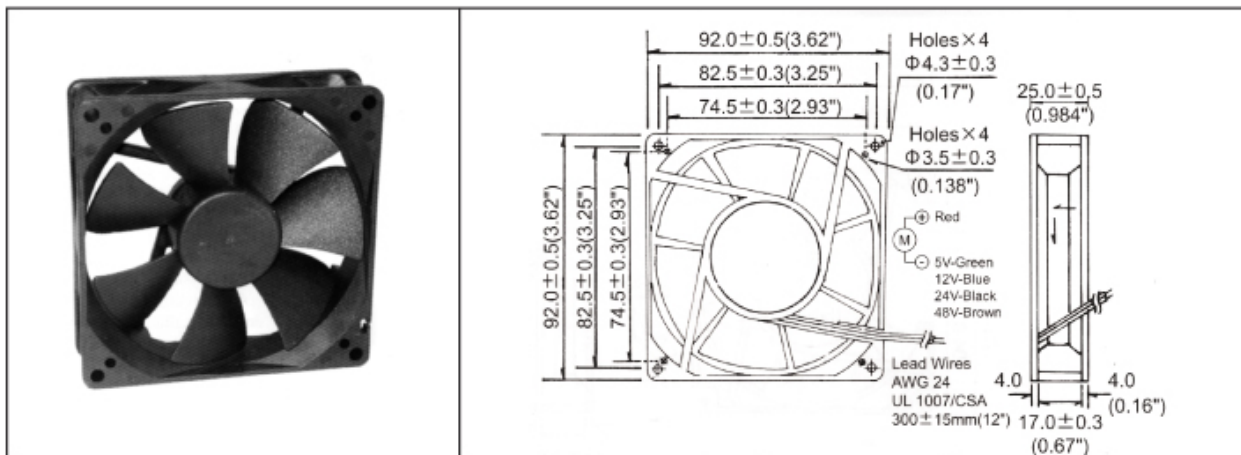

Frame & Impeller	PBT, UL94V-O plastic	Available Options: Tachometer (FG) Alarm (RD) <u>Life Expectancy (L10)</u> Ball Bearing 60,000 hours (L10 at 40C) Sleeve Bearing 30,000 hours (L10 at 40C) <u>Operating Temperature</u> Ball Bearing -20C ~ +80C Sleeve Bearing -10C ~ +50C	
Connection	2x Lead wires		
Motor	Brushless DC, auto restart, polarity protected		
Bearing System	Dual Ball or Sleeve		
Insulation Resistance	10M ohm between leadwire and frame (500VDC)		
Dielectric Strength	1 second at 500 VAC, max leakage - 500 MicroAmp		
Storage Temperature	-30C ~ +90C		

Model Number	Speed (RPM)	Airflow (CFM)	Noise (dB)	Volts DC	Voltage Range	Amps	Max. Static Pressure (\"H ₂ O)
OD9225-05H*	2400	45	30	05	4~7	0.32	0.22
OD9225-05M*	2000	35	27	05	4~7	0.25	0.17
OD9225-05L*	1600	25	20	05	4~7	0.18	0.12
OD9225-12H*	2800	50	33	12	7~17	0.29	0.24
OD9225-12M*	2400	35	30	12	7~17	0.20	0.18
OD9225-12L*	1800	25	23	12	7~17	0.12	0.12
OD9225-24H*	2800	50	33	24	12~28	0.18	0.24
OD9225-24M*	2400	35	30	24	12~28	0.12	0.18
OD9225-24L*	1800	25	23	24	12~28	0.10	0.12
OD9225-48HB	2800	50	33	48	32~56	0.12	0.24

* Indicate "B" to specify Ball bearing or "S" to specify Sleeve bearing

10557 Metric Drive
Dallas, Texas 75243
214-340-0265



OrionFans.com
Information and data is subject to change without prior notification.