


THERMOCOOL AXIAL FANS

THERMOCOOL



RoHS

Thermocool Axial Fans provide enhanced cooling for a variety of electronic devices. Leading air flow technology is designed into every Thermocool product resulting in reduced turbulence, low noise levels and a more energy efficient product. Thermocool fans are ideal for use in computer systems, portable CD and DVD players, stereo components, overhead projectors, laptop computers, and many other electronic applications where circulation is a key concern.

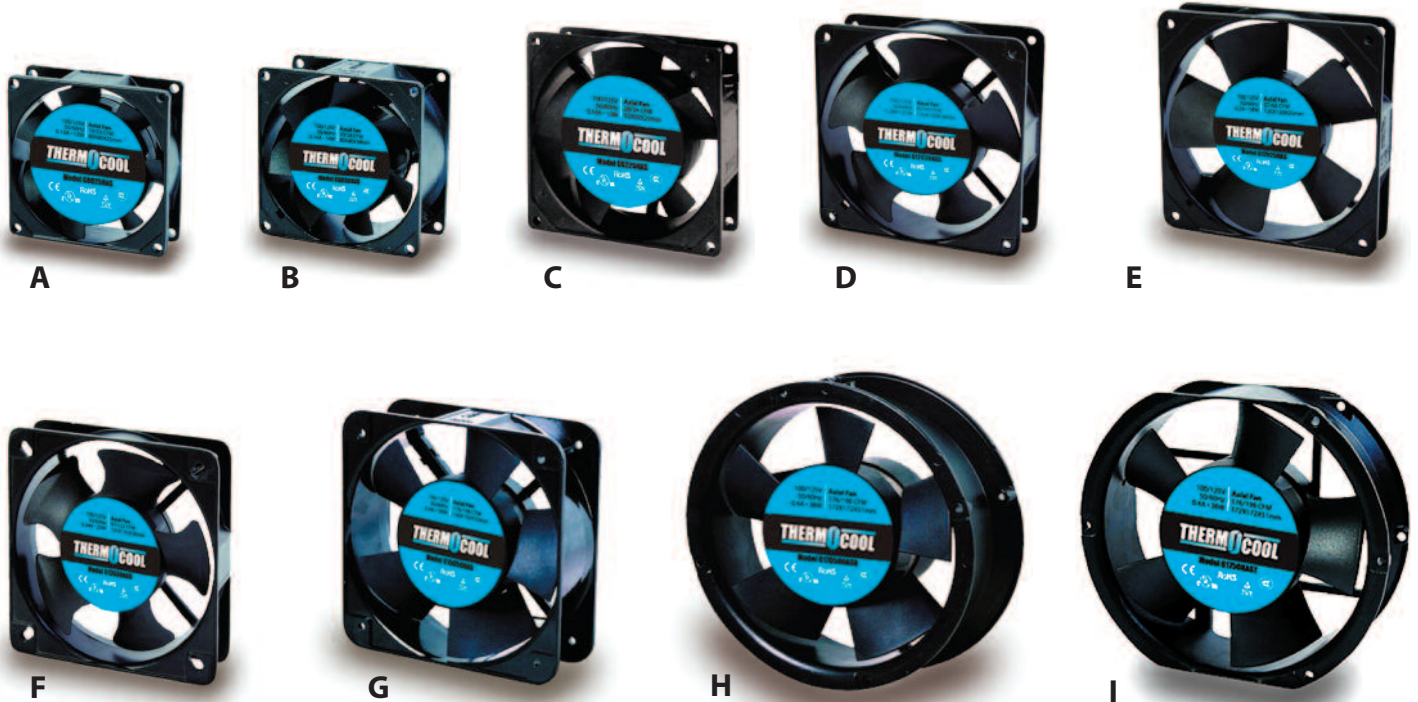

	PART NUMBER	BEARING SYSTEM	VOLTAGE LEAD TYPE	FREQ. (HZ)	AMPS	WATTS	SPEED	NOISE (DB)	AIR FLOW (CFM)	SIZE (MM)	SIZE (INCH)
A	G8025HAS	Sleeve	100/125*	50/60	0.13	13	2300/2700	27/30	19/23	80X80X25	3.15X3.15X.98
B	G8038HAS	Sleeve	100/125*	50/60	0.14	14	2400/2900	28/33	23/28	80X80X38	3.15X3.15X1.5
C	G9225HAS	Sleeve	100/125†	50/60	0.14	13	2300/2800	34/40	28/34	92X92X25	3.62X3.62X.98
D	G12025HAS	Sleeve	100/125†	50/60	0.2	18	2300/2700	39/42	57/66	120X120X25	4.72X4.72X.98
E	G12038HAS	Sleeve	100/125†	50/60	0.28	21	2600/3000	43/48	82/95	120X120X38	4.72X4.72X1.5
	G12038MAB	Ball	100/125†	50/60	0.22	19	2200/2600	39/44	72/85	120X120X38	4.72X4.72X1.5
	G12038MAS	Sleeve	100/125†	50/60	0.22	19	2200/2600	39/44	72/85	120X120X38	4.72X4.72X1.5
F	G13538HAS	Sleeve	100/125*	50/60	0.34	25	2400/2800	46/53	97/122	135X135X38	5.31X5.31X1.5
G	G15050HAS	Sleeve	100/125*	50/60	0.4	38	2600/2900	54/59	176/198	150X150X50	5.9X5.9X2
H	G17050HASB	Ball	100/125†	50/60	0.4	38	2600/2900	54/59	176/198	172X172X51	6.77X6.77X2
I	G17050HAST	Sleeve	100/125†	50/60	0.4	38	2600/2900	54/59	176/198	172X150X51	6.77X5.9X2