



## SPECIFICATIONS SHEET

**PRODUCT TYPE : PIEZO BUZZER**

**PRODUCT SERIES : SL12A**

**DESCRIPTION : PZ BUZZER F. DUAL 12V PLG ABS RoHS**

**COLOR : BLACK**


### ELECTRICAL SPECIFICATIONS

MODEL NO.	SL12ADF3120LFEA	
OPERATING VOLTAGE RANGE ( VDC )	6.0 ~ 28.0	
RATED VOLTAGE ( VDC )	12.0	
* MAX. RATED CURRENT ( mA )	20.0	
* MIN. SOUND OUTPUT ( dBA/ 30.0 cm )	90.0	
* FREQUENCY ( Hz )	2900.0 ± 500.0	
TONE NATURE	SINGLE / FAST PULSE ( PULSE RATE 110.0 ~ 130.0 WITH 1 MINUTE )	
OPERATING TEMPERATURE ( °C )	- 20.0 ~ + 60.0	
STROAGE TEMPERATURE ( °C )	- 30.0 ~ + 70.0	
TERMINAL	PLUG	
HOUSING MATERIAL	ABS	
WEIGHT ( g )	35.0	

\* Value applying at rated voltage

### DIMENSIONS

UNIT : mm Tolerance : ± 0.5 mm

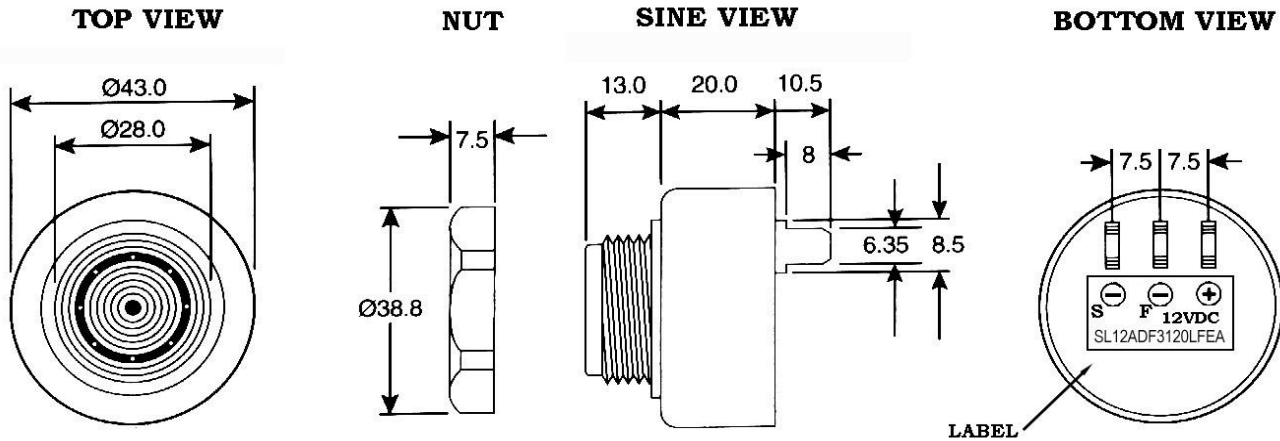

Approved By :   
Date : 5-Apr.-2017

Prepared By :   
Date : 5-Apr.-2017

Modify :	Date :	By :
Add " PULSE RATE 110.0 ~ 130.0 WITH 1 MINUTE " information	5-Apr.-2017	Nelson