



IDC Flat Cable D-Sub, Male Plugs

156-1609, 156-1615, 156-1625, 156-1637

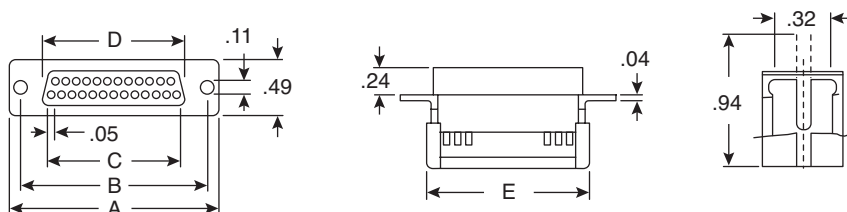

IDC Flat Cable D-Sub, Male Plugs

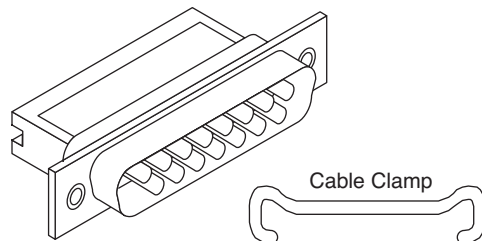

Dimensions: In.

Mouser Stock No.	Pin	A	B	C	D	E
156-1609	9M	1.2	.98	.43	.70	.65
156-1615	15M	1.5	1.3	.76	.98	.97
156-1625	25M	2.1	1.8	1.3	1.6	1.5
156-1637	37M	2.7	2.5	1.9	2.2	2.2

SPECIFICATIONS	
Shell:	Steel zinc plated
Socket Contact:	Phospor bronze gold plated over nickel 3 micro/inch
Insulator:	PBT and 30% glass fiber reinforced
Current Rating:	1A
Dielectric Strength:	1000V for 1 minute
Insulator Resistance:	1000MΩ min. @ 500VDC
Temperature:	-55°C ~ +105°C
Standard:	.05 pitch

156-1609, 156-1615, 156-1625, 156-1637

Date Last Revised: 10-18-05

KC-300672