


IEC 60320 C14 Inlet

161-R301B07



IEC 60320 C14 Inlet

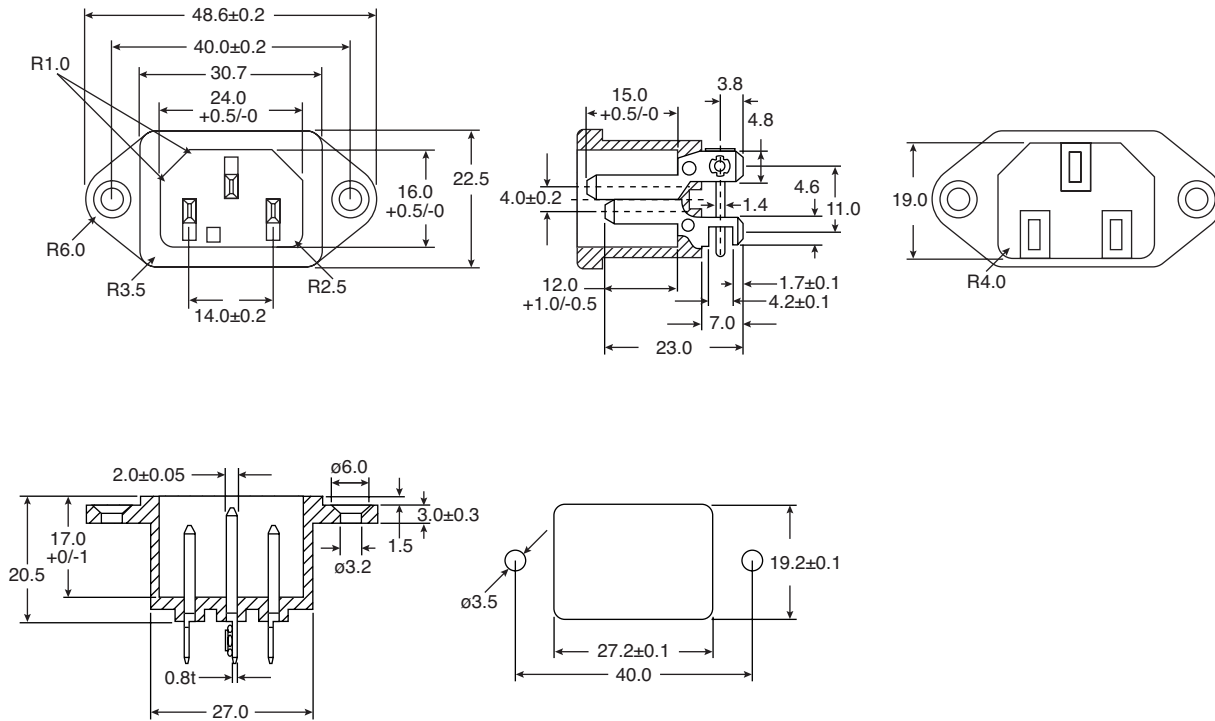

Dimensions: mm

SPECIFICATIONS	
Rating:	10A, 250VAC
Insulation Resistance:	Over 100M Ω at 500VDC
Dielectric Strength:	2000VAC for 1 minute

Materials	
Body:	Black Glass-Fiber Thermoplastic

Tolerance
X.XX ± 0.1
XX.XX ± 0.2
XXX.XX ± 0.3

Date Last Revised: 10-17-05

KC- 300199

161-R301B07