


# Audio Power Points

174-R130B-EX, 174-R130R-EX



Audio Power Points

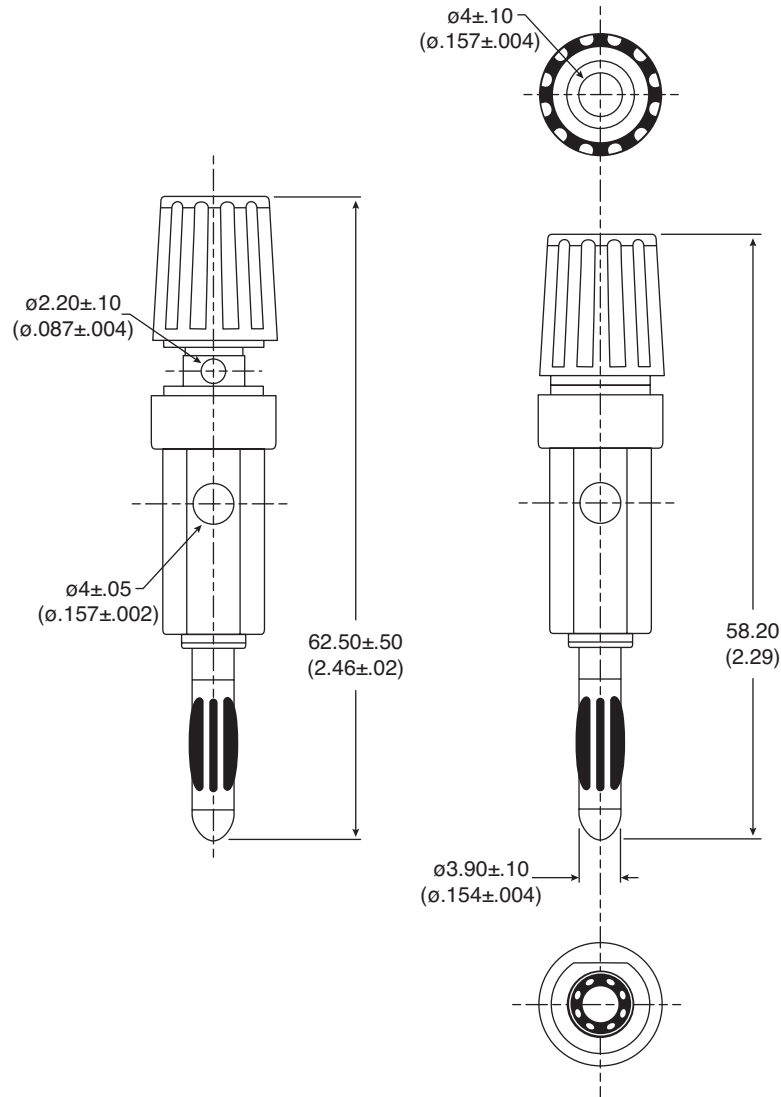

Dimensions: mm (in.)

## SPECIFICATIONS

<b>Current Rating:</b>	10A/250V AC
<b>Insulator Resistance:</b>	500VDC 100M $\Omega$ min.
<b>Operating Temperature:</b>	-10°C to +80°C
<b>Dielectric Strength:</b>	1000VAC 1 minute
RoHS Compliant by Exemption	

## MATERIALS

<b>Insulation:</b>	Nylon
<b>Metal:</b>	Nickel plated brass

Date Last Revised: 3-6-07

174-R130B-EX, 174-R130R-EX

KC-301103