

CENTER-TAPPED POWER TRANSFORMERS


Primary Input Voltage 117vac

Output Voltage 12VCT, 24VCT
and 48VCT

Solder Lug/Push-on Terminals

Class A Rated @ 105°C Insulated

1,000 Volt Hi-Pot Tested

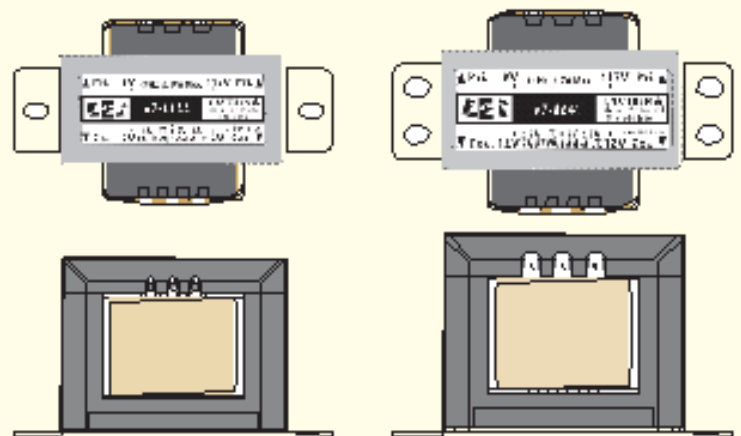

SPECIFICATIONS

Part Number	Rated Output Voltage*	Current Rating	Frame Size	Mounting Hole Center to Center	Overall Thickness/Width (Inches) (Excluding Mounting Tabs)	Height
67-1120	12vac	500ma	EI-41x14.5	2.07"	1.29 x 1.69	1.41"
67-1121	12vac	1 amp	EI-41x16.5	2.07"	1.37 x 1.69	1.41"
67-1122	12vac	2 amp	EI-48x20B	2.36"	1.57 x 1.96	1.67"
67-1123	12vac	3 amp	EI-57x19A	2.79"	1.73 x 2.32	2.0"
67-1124	12vac	4 amp	EI-57x25B	2.79"	1.95 x 2.32	2.0"
67-1125	12vac	5 amp	EI-66x25B	3.14"	2.12 x 2.67	2.28"
67-1240	24vac	500ma	EI-41x16.5	2.07"	1.37 x 1.69	1.41"
67-1241	24vac	1 amp	EI-48x20B	2.36"	1.57 x 1.96	1.67"
67-1242	24vac	2 amp	EI-57x25B	2.79"	1.95 x 2.32	2.0"
67-1243	24vac	3 amp	EI-66x30	3.14"	2.29 x 2.67	2.28"
67-1244	24vac	4 amp	EI-76x30	3.62"	2.42 x 3.1	2.65"
67-1245	24vac	5 amp	EI-76x35A	3.62" x 2 rows in 0.72" pitch	2.64 x 3.1	2.65"
67-1483	48vac	3 amp	EI-76x40B	3.62" x 2 rows in 0.72" pitch	2.84 x 3.1	2.65"