


Dimensions: mm (In.)

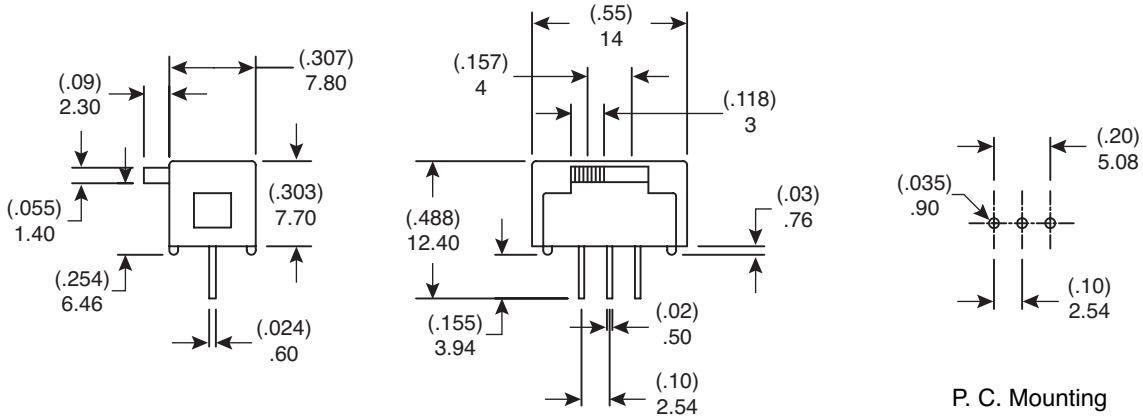

POS.1	POS.2	POS.3
ON	NONE	ON
2-1	OPEN	2-3

Switch Function

**Electrical Specifications:**

- Rating: 1A/ 250VAC  
3A/ 120VAC or 28 VDC
- Contact Resistance: 50mΩ max. initial
- Insulation Resistance: 1000MΩ min.
- Dielectric Strength: 1000 V RMS @ sea level
- Breaking Capacity: 1A 250VAC
- Minimum Load: 100mA

**Mechanical Specifications:**

- Mechanical Life: 20,000 cycles
- Operating Temperature: -30°C to 85°C

**Note:**

- RoHS Compliant

**Materials:**

- Case: Nylon, white
- Actuator: Nylon, black
- Housing: Nylon, black
- Contact: Silver plated copper alloy
- Terminals: Silver plated copper alloy

Miniature Slide Switch  
103-5003-EV

