


Dimensions: mm (In.)

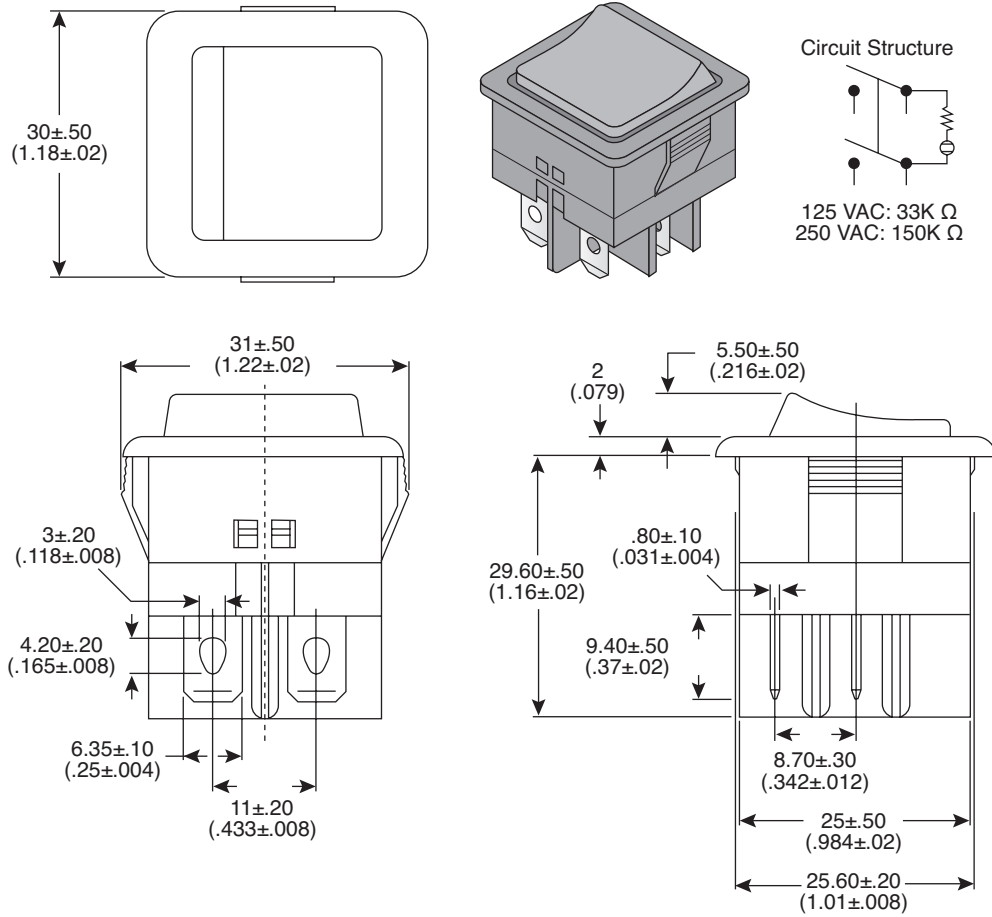

Electrical Specifications:

- Rating: 16A / 125VAC, 10A / 250 VAC
- Contact Resistance: 50m Ω max.
- Insulation Resistance: 500 VDC 100M Ω min.
- Dielectric Strength: 1500 VAC for 1 minute

Mechanical Specifications:

- Operating Temperature: -20°C ~ 85°C
- Circuit: 4P DPST Off-On
- Neon Lamp: 110VAC

Note:

- RoHS Compliant

Illuminated Rocker Switch
103-7077-EV

