
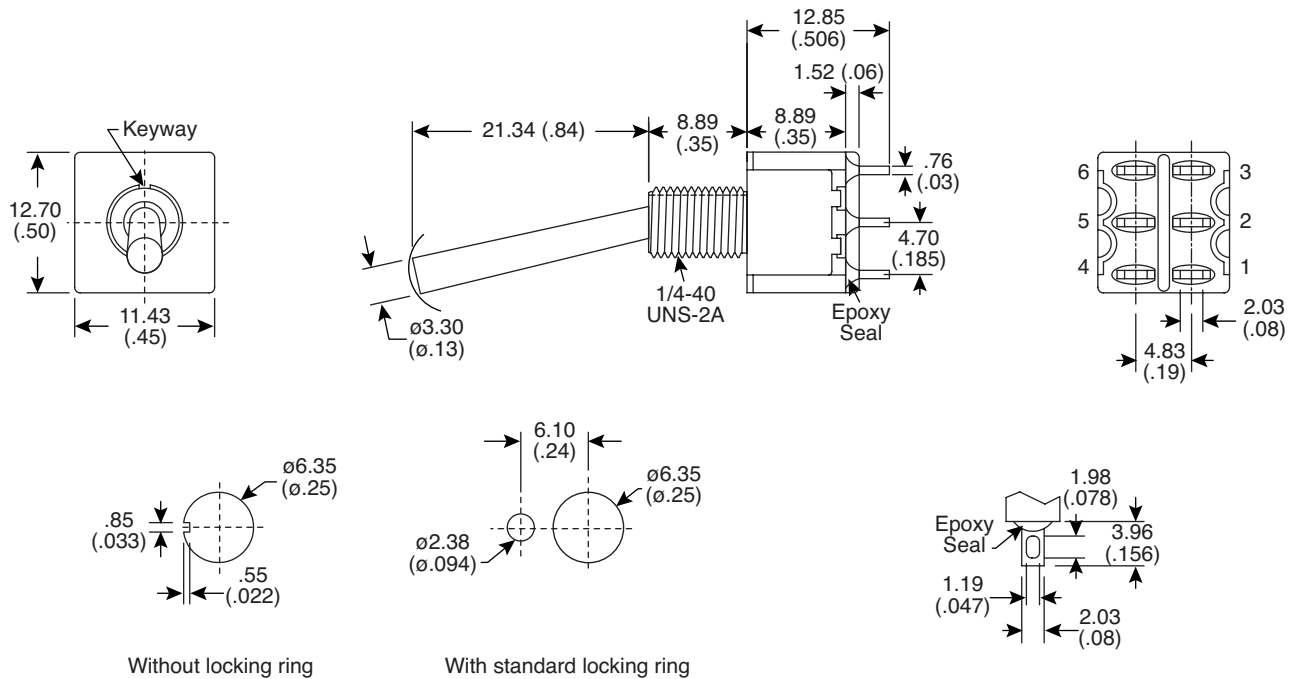


Dimensions: mm (In.)

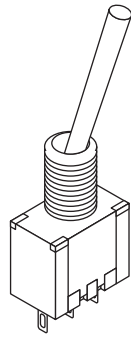

Panel Mounting

Solder Lug

Mechanical Specifications:

- Mechanical Life: 40,000 make-and-break cycles
- Operating Temperature: -30°C ~ 85°C

Electrical Specifications:

- Rating: 2A/250VAC, 5A/120VAC or 28VDC
- Contact Resistance: 10mΩ max. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000MΩ min.
- Dielectric Strength: 1,000VRMS @ sea level

Materials:

- Case: Diallyl phthalate (DAP)
- Actuator: Brass, chrome plated
- Bushing: Brass, nickel plated
- Housing: Stainless Steel
- Terminal/Contact: Silver or gold plated

Note:

- RoHS compliant by exemption

Stock No.	Type	Circuit
108-0029-EVX	DPDT	On-On
108-0031-EVX	DPDT	On-Off-On

Miniature Toggle Switches
108-0029-EVX, 108-0031-EVX

