




Dimensions: mm (In)

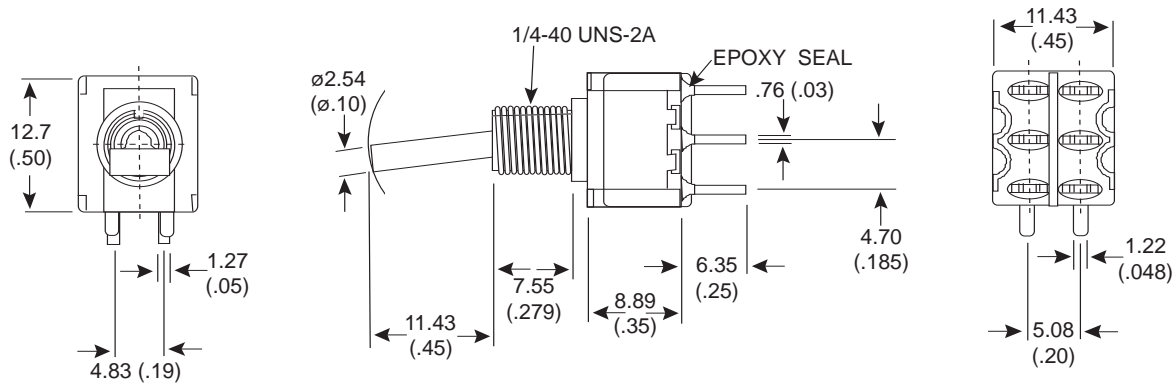

P.C. MOUNTING

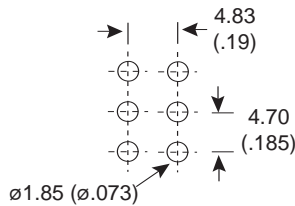

PANEL MOUNTING

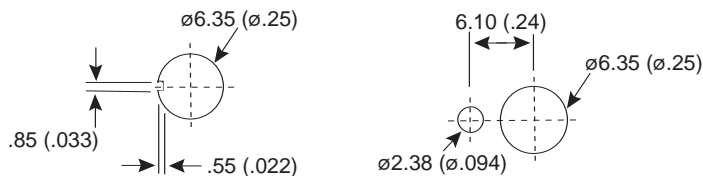

Without locking ring.

With standard locking ring.

SWITCH FUNCTION

| POS.1 | POS.2 | POS.3 |
|---------|-------|---------|
| | | |
| ON | NONE | ON |
| 2-3,5-6 | OPEN | 2-1,5-4 |
| | | |

Electrical Specifications:

- Electrical Life: 40,000 make-and-break cycles at full load
- Contact Resistance: 10mΩ max. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000MΩ min.
- Dielectric Strength: 1,000 V RMS@ sea level.
- Rating: 2A/250 VAC, 5A/120VAC or 28VDC

Mechanical Specifications:

- Operating Temperature: -30°C to +85°C

Materials:

- Case: Diallyl phthalate (DAP) (UL94v-0)
- Actuator: Brass, chrome plated.
- Bushing: Brass, nickel plated.
- Housing: Stainless steel.
- Terminal/Contact: Silver or Gold plated.
- Switch Support: Brass, Tin plated.

Toggle Switch

108-1MD1T6B11M2QE

