




12mm Potentiometers
RV120D-20-15A Series

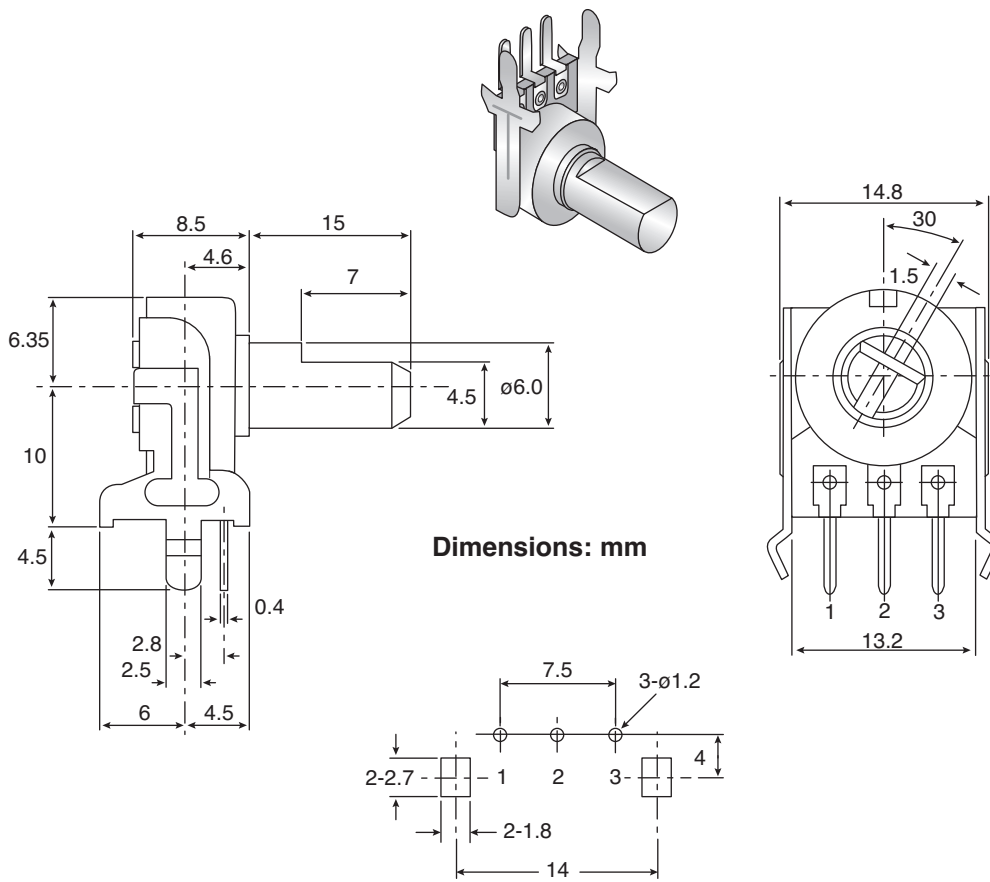

Dimensions: mm

P.C.B. Mounting Hole Detail

Specifications:

- Rotation Angle: degree $300 \pm 5^\circ$
- Flat "D" Shaft: 60mm Diameter
- Termination: PC terminal
- Rotations Life: 15,000 cycles
- Rated Wattage: Linear-0.08W
 Audio-0.04W
- Max. Working Voltage: Linear-150V
 Audio-100V

Tol. Unless Otherwise Stated		
Less Than	10	± 0.3
Above	10-30	± 0.5
Above	30~100	± 1.0
Above	---	$\pm 5^\circ$

Alpha Part Number	Value	Taper
RV120D-20-15A-A1K	1K	Audio
RV120D-20-15A-A5K	5K	Audio
RV120D-20-15A-A10K	10K	Audio
RV120D-20-15A-A50K	50K	Audio
RV120D-20-15A-A100K	100K	Audio
RV120D-20-15A-A500K	500K	Audio
RV120D-20-15A-A1M	1M	Audio
RV120D-20-15A-B1K	1K	Linear
RV120D-20-15A-B5K	5K	Linear
RV120D-20-15A-B10K	10K	Linear
RV120D-20-15A-B50K	50K	Linear
RV120D-20-15A-B100K	100K	Linear
RV120D-20-15A-B500K	500K	Linear
RV120D-20-15A-B1M	1M	Linear