

COMMONWEALTH AC AXIAL FAN

FP-108JC


92x92x38mm PLUTO




DESIGN FEATURES

- ***BEARING SYSTEM:** SLEEVE BEARING & BALL BEARING
- ***IMPELLER:** PLASTIC WITH FIBER GLASS FILLED UL 94V-0
- ***HOUSING:** DIE CAST ALUMINUM PAINTED BLACK OR NATURAL COLOR
- ***MOTOR:** SHADED POLE, IMPEDANCE PROTECTED
- ***CONNECTING:** WIRE LEADS
- ***SPEED:** S-1 HIGH SPEED TYPE
S-2 MEDIUM SPEED TYPE
S-3 LOW SPEED TYPE
- ***OTHER VOLTAGE:** 24 ,48, 100, 380AC (50/60Hz) ARE AVAILABLE

DIMENSIONS:MM

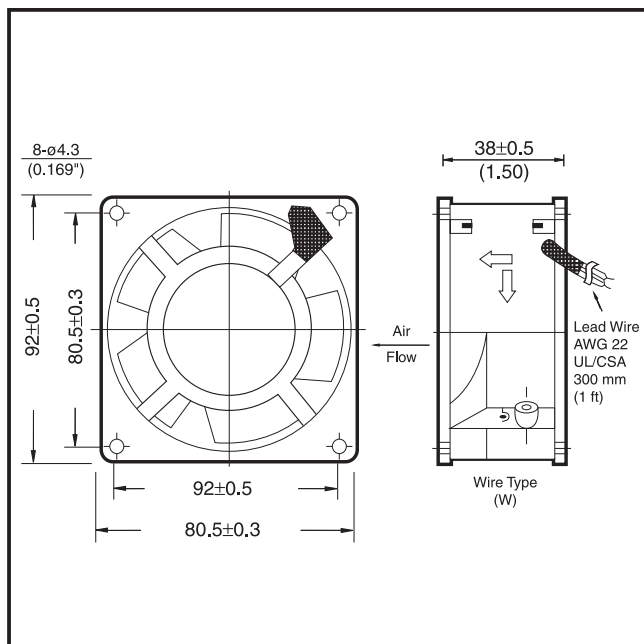

PERFORMANCE

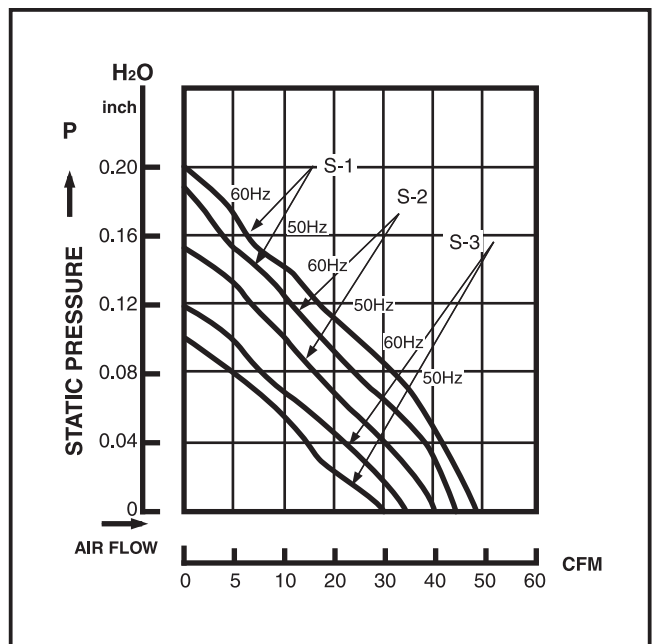

SPECIFICATIONS

Specifications are subject to change without notice

MODEL NO.	VOLT (VAC)	FREQUENCY (HZ)	AIR (CFM)	VOLUME (M ³ /MIN)	CURRENT (A)	POWER (W)	SPEED (RPM)	STATIC PRESSURE (INCH-H ₂ O)	NOISE (dBA)
FP-108JC (S-1)	110/120	50/60	40/45	1.10/1.30	0.15/0.12	10/9	2700/3000	0.17/0.20	35/37
FP-108JC (S-1)	220/240	50/60	40/45	1.10/1.30	0.15/0.12	16/13	2700/3000	0.17/0.20	35/37
FP-108JC (S-2)	110/120	50/60	33/40	0.93/1.10	0.12/0.10	8.5/7.0	2300/2500	0.14/0.15	24/25
FP-108JC (S-2)	220/240	50/60	33/40	0.93/1.10	0.10/0.08	14/11	2300/2500	0.14/0.15	24/25
FP-108JC (S-3)	110/120	50/60	27/30	0.76/0.85	0.09/0.07	7.0/6.0	2000/2200	0.10/0.11	22/24
FP-108JC (S-3)	220/240	50/60	27/30	0.76/0.85	0.09/0.07	11/9.0	2000/2200	0.10/0.11	22/24