



NEMA Receptacle UL498 5-15R

0709 Series


Power Rating : 15A 125V AC

Insulation Resistance : over 100MΩ 500V DC

Withstanding Voltage : 2,000V AC One Minute



Operating Rating Temperature : -25°C to +85°C

Main Unit Material : Thermoplastic UL Flammability
94V-0 & Copper Alloy

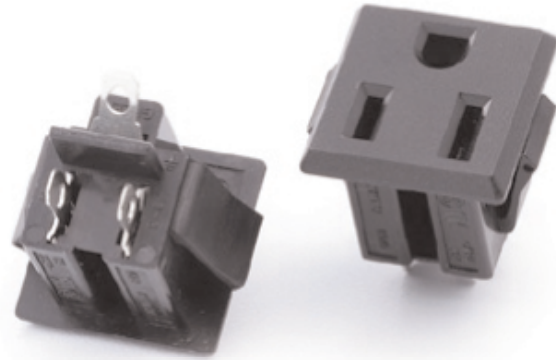


2-Pole 3-Wire Grounding Receptacle




Unit:mm

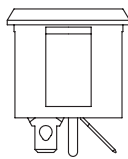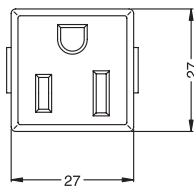

0709-PQ

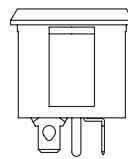

0709-PQA

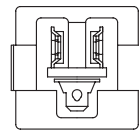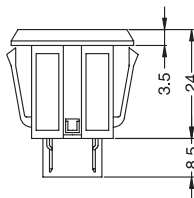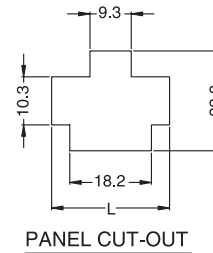

ORDER NO.	CODE	PANEL THICKNESS	L	TERMINAL
0709-PQ 0709-PQA	Q	0.8	24	4.8mm/.187" Q.D./SOLDER TAB
		1.0	24.6	
		1.2	25.2	
		1.6	26.2	

