

Distributed by:

JAMECO[®]
ELECTRONICS

www.Jameco.com ♦ 1-800-831-4242


The content and copyrights of the attached
material are the property of its owner.

Jameco Part Number 228494


Audio Patch Cords

Suitable for General Audio Applications
 2.8mm OD Black PVC Jacket
 4.5mm OD Black PVC Guitar Cord Jacket
 Fully Molded Construction
 Nickel-plated connectors provide superior protection against corrosion
 AWG26 Stranded Copper Center Conductor
 Low-Loss 95% Spiral-Wound Copper Shield
 99.99% Pure Oxygen-Free Copper Wire


- 255-155** 2' 3.5mm Mono Plug to Plug
- 255-160** 6' 3.5mm Mono Plug to Plug
- 255-165** 10' 3.5mm Mono Plug to Plug
- 255-170** 6' 3.5mm Mono Plug to RCA Plug
- 255-185** 10' Coiled 3.5mm Extension Cable
3.5mm Stereo-Plug to Stereo-Jack
- 255-187** 25' Coiled 3.5mm Extension Cable
3.5mm Stereo-Plug to Stereo-Jack
- 255-190** 25' Guitar Replacement Cable
1/4" Mono-Plug to 1/4" Mono-Plug
- 255-195** 25' Coiled 1/4" St Extension Cable
1/4" Stereo-Plug to 1/4" Stereo-Jack
- 255-255** 2' 3.5mm Stereo Plug to Plug
- 255-258** 6' 3.5mm Stereo Plug to Plug
- 255-262** 12' 3.5mm Stereo Plug to Plug
- 255-264** 25' 3.5mm Stereo Plug to Jack
- 255-265** 6' 3.5mm Stereo Plug to Jack
- 255-268** 12' 3.5mm Stereo Plug to Jack
- 255-269** 25' 3.5mm Stereo Plug to Jack

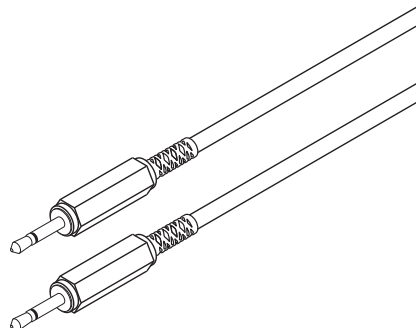


255-155 2' Mono
255-160 6' Mono
255-165 10' Mono

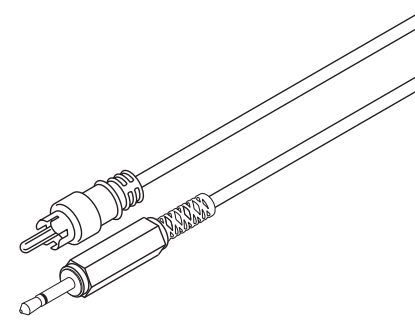


255-170 6' Mono

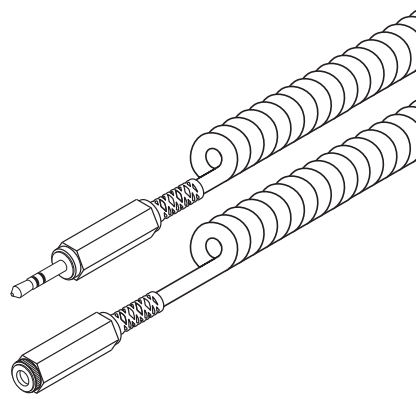


255-185 10' Stereo
255-187 25' Stereo

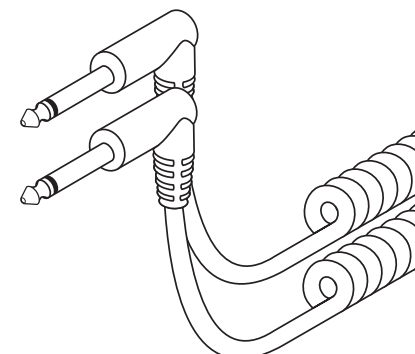


255-190 25' Mono

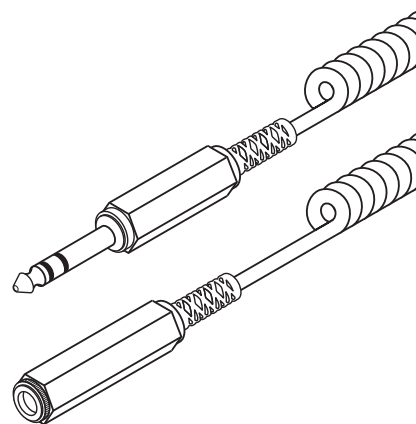

255-195 25' Stereo

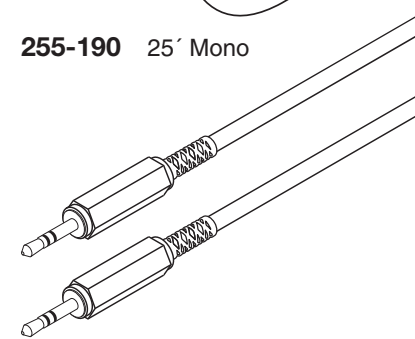

255-255 2' Stereo
255-258 6' Stereo
255-262 12' Stereo
255-264 25' Stereo

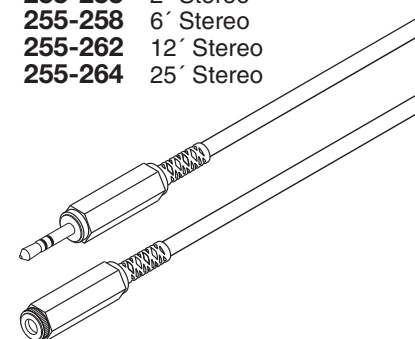


255-265 6' Stereo
255-268 12' Stereo
255-269 25' Stereo


Microphone Cables

Professional Quality Microphone Cables
 Suitable for Microphones, Musical Instruments,
 and Home Entertainment Systems
 Reliable Transmission of Audio Frequencies
 Minimize hum and cross-talk interference
 6.0mm OD Black Flexible Rubber Jacket
 Low-Loss Heavy Gauge Cable
 Nickel-Plated Zinc-Alloy XLR Connectors
 7x0.25mm AWG22 Center Conductors
 Low-Loss 95% Spiral-Wound Copper Shield
 99.99% Pure Oxygen-Free Copper Wire

- 255-290** 20' Microphone Cable
1/4" Mono-Plug to 3-Pin XLR Jack
- 255-293** 60' Microphone Cable
1/4" Mono-Plug to 3-Pin XLR Jack
- 255-295** 20' Microphone Extension Cable
3-Pin XLR Plug to XLR Jack
- 255-298** 60' Microphone Extension Cable
3-Pin XLR Plug to XLR Jack

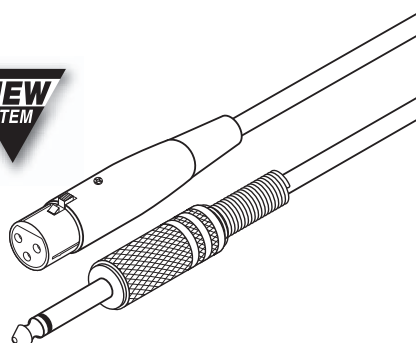

255-290 20'
255-293 60'

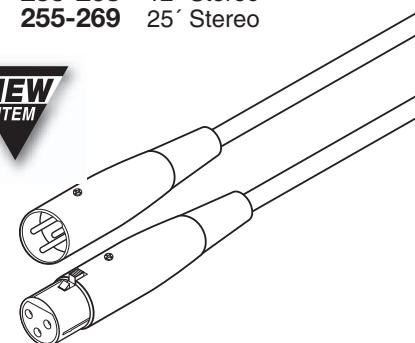

255-295 20'
255-298 60'