


AC AXIAL FAN FP-108-1

M3


FP-108-1 Size: 119 x 119 x 38 mm / 4.71"W x 4.71"H x 1.5"T
Weight: 550 g
Bearing System: Sleeve Bearing and Ball Bearing
Impeller: Plastic with fiber glass fill, UL 94V-0
Housing: Die-cast aluminum, painted Black or Natural Colour; PBT Plastic, UL-94V-0
Motor: Shaded pole, impedance protected
Connection: Terminal(T) and Wire leads(W)
Speed: S-1: High Speed Type
 S-2: Medium Speed Type
 S-3: Low Speed Type
Other Voltages: 24V, 48V, 100V, 380VAC (50/60Hz) are available



DIMENSIONS

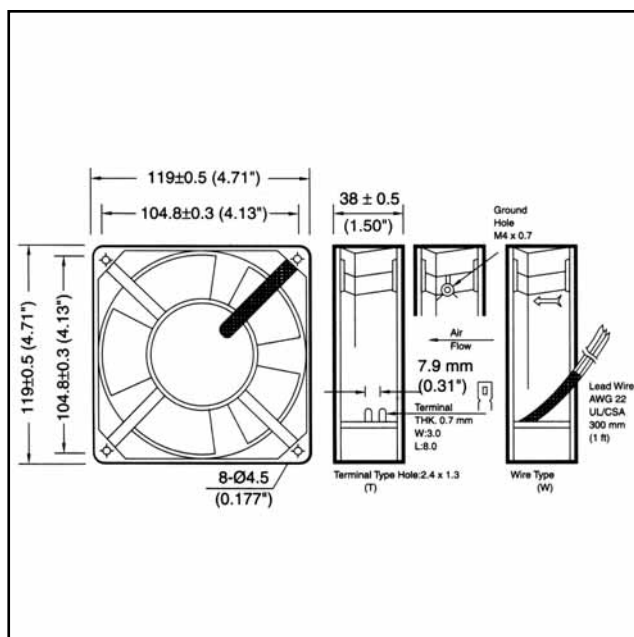

PERFORMANCE

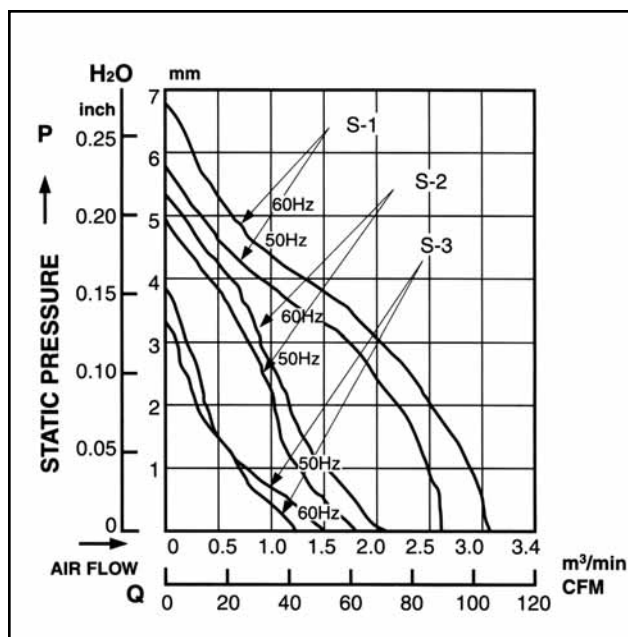

SPECIFICATIONS

ITEM NUMBER	VOLTAGE (VAC)	FREQUENCY (HZ)	AIR (CFM)	VOLUME (M ³ /MIN)	CURRENT (A)	POWER (W)	SPEED (RPM)	STATIC PRESSURE (INCH-H ₂ O)	NOISE (DBA)
**NEW FP-108-1 (S-ULTRA)	110/120	50/60	112/120	3.18/3.40	0.25/0.19	18/19	2,700/3,000	0.27/0.30	40/45
	220/240	50/60	112/120	3.18/3.40	0.14/0.12	18/19	2,700/3,000	0.27/0.30	40/45
FP-108-1 (S-1)	110/120	50/60	80/105	2.3/3.0	0.24/0.18	18/17	2,700/3,000	0.23/0.28	42/47
FP-108-1 (S-1)	220/240	50/60	80/105	2.3/3.0	0.13/0.11	18/17	2,700/3,000	0.23/0.28	42/47
FP-108-1 (S-2)	110/120	50/60	63/71	1.65/1.85	0.13/0.12	11/10	2,200/2,500	0.19/0.21	37/39
FP-108-1 (S-2)	220/240	50/60	63/71	1.65/1.85	0.11/0.09	11/10	2,200/2,500	0.19/0.21	37/39
FP-108-1 (S-3)	110/120	50/60	54/52	1.5/1.4	0.11/0.10	9/8	1,800/2,000	0.16/0.15	30/34
FP-108-1 (S-3)	220/240	50/60	54/52	1.5/1.4	0.08/0.06	9/8	1,800/2,000	0.16/0.15	30/34

Fans