 




**RoHS** (2002/95/EC) COMPLIANT

CUSTOMER: P/N: 2500.PS8-R REV. APPROVED BY:

REVISIONS			
REV.	DESCRIPTION	DATE	APPVD.
▲			
▲			
▲			
▲			

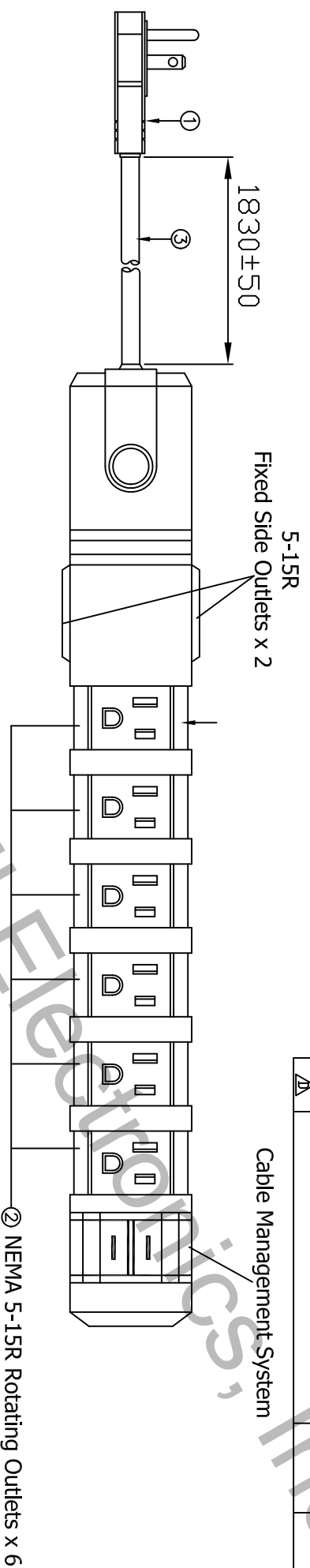

① NEMA 5-15P  
360° ROTATING

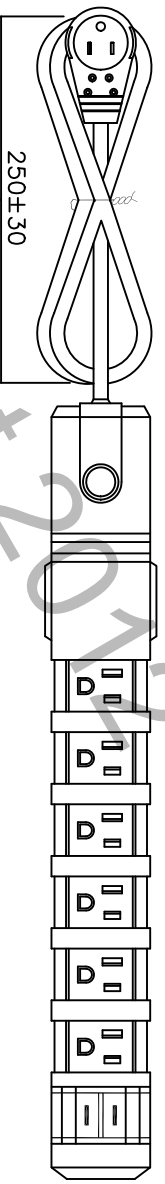

**FEATURES:**

Part Number:	2500.PS8-R
Number of Pivoting Outlets:	6
Number of Fixed Outlets:	2
Max Output:	1800 Watts
LED Surge Indicator:	Yes
Fireproof X3MOV Surge Protection:	Yes
Power Switch:	Yes
Circuit Breaker:	15A
Joules of Surge Protection:	2160J
Clamping Voltage:	330V
Max Spike Amps:	144,000A
(Lifetime Rating)	
Max Spike Volts:	6KV
(Lifetime Rating)	
Response Time:	<1 nanosecond
Circuit Breaker Rating:	15A
EMI/RFI Removal:	40 decibels

**PRODUCT SPECIFICATION:**

COLOR: BEIGE

- (1) PLUG: NEMA 5-15P ROTATING APPROVAL: UL,C-UL
- (2) RECEPTACLE: NEMA 5-15R 180° ROTATING X 6 APPROVAL: UL,C-UL
- (3) RECEPTACLE: NEMA 5-15R FIXED X 2 APPROVAL: UL,C-UL
- (4) CABLE: SJT 105°C 14AWGx3C APPROVAL: UL,C-UL

ENGINEER:	SIGNATURE	<p><b>QUAIL ELECTRONICS, INC.</b> http://www.quail.com</p>	PRODUCT NO.:	DATE: DATE: 2005.07.01
MANAGER:			UNIT: mm	SHEET: 1 OF 1
CHECKED BY:			DWG NO.:	REV.:
DRAWN BY:				

THE INFORMATION CONTAINED HEREIN IS PROPRIETARY TO QUAIL ELECTRONICS, INC. ANY USE OR DISCLOSURE OF THIS INFORMATION, EXCEPT FOR THE EXCLUSIVE BENEFIT OF QUAIL ELECTRONICS, INC. IS PROHIBITED.