



Jave Yuan
Electric Wire Co., Ltd.

website: www.javeyuan.com
e-mail: info@javeyuan.com


Address: No.235, Nanping Road, Pingzhen Dist., Taoyuan City, Taiwan
TEL: 886 3 4398788 FAX :886 3 4397389

CABLE SPECIFICATION

Model: SPW20
(61-3020-50、61-3020-100、61-3020-500、61-3020-1000)
Type: DC Power Cable
Specification: (16/0.20MM BC)X2F
Marketing: NONE
Appearance:

Shape	Color	Length	Package
Circle X2	Red/Black	50 Feet	Plastic Spool
		100 Feet	
		500 Feet	
		1000 Feet	

Construction:

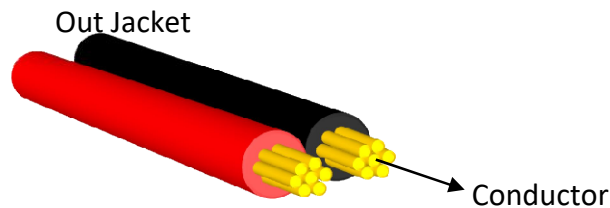

Conductor

Material: Bare Copper (OFC)
Construction: 16 X 0.20 MM
Cross Section: AWG20 (0.50 MM²) X 2

Out Jacket

Material: Polyvinylchloride (PVC)
Thickness: 0.67 MM
Diameter: 2.3 X 4.6 MM

Operation Temp.: -20⁰C ~ 75⁰C

Electric Characteristic

Voltage Rating: 300 V
Conductor Resistance: 36.5 Ω/KM

Approval By: