

Distributed by:





www.Jameco.com ♦ 1-800-831-4242

The content and copyrights of the attached material are the property of its owner.

NICHIBO DC MOTOR

Jameco Part Number 231925
(FE-260-2295)

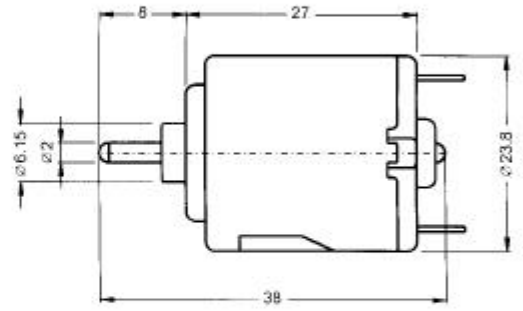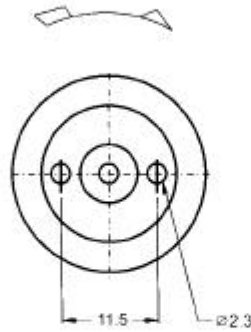

代表的用途：玩具
Typical Application：Motorized Toy

WEIGHT：30g(APPROX)

| MODEL | VOLTAGE | | NO LOAD | | AT MAXIMUM EFFICIENCY | | | | | STALL | |
|--------------|-----------------|----------------|---------|---------|-----------------------|---------|--------|--------|-------|---------|--------|
| | OPERATING RANGE | NOMNAL | SPEED | CURRENT | SPEED | CURRENT | TORQUE | OUTPUT | EFF | CURRENT | TORQUE |
| | | | rpm | A | rpm | A | g-cm | W | % | A | g-cm |
| FE-260-2670 | 1.5 - 3.0 | 1.5V CONSTANT | 5100 | 0.180 | 3700 | 0.66 | 10.53 | 0.40 | 42.92 | 2.41 | 50.08 |
| FE-260-2295 | 1.5 - 4.5 | 3.0V CONSTANT | 8100 | 0.180 | 6850 | 0.63 | 13.96 | 0.98 | 53.91 | 2.62 | 73.29 |
| FE-260-18130 | 1.5 - 4.5 | 3.0V CONSTANT | 6100 | 0.100 | 4780 | 0.36 | 10.27 | 0.50 | 49.63 | 1.39 | 52.75 |
| FE-260-08450 | 6.0 - 12.0 | 12.0V CONSTANT | 7500 | 0.035 | 5560 | 0.11 | 10.32 | 0.60 | 46.63 | 0.35 | 42.00 |

