

HCM-12

■ SERIES

■ FEATURES



- Sealed Structure
- Wave Solderable & Washable

■ SPECIFICATION

TYPE	HCM-1201	HCM-1206	HCM-1212
RATED VOLTAGE D.C	15	6	12
WORKING VOLTAGE D.C (V)	1~2	4~8	7~16
RATED CURRENT D.C (mA)	≤70	≤40	≤40
A.C RESISTANCE (Ω)	16	80	240
D.C RESISTANCE (Ω)	6.5 ± 1	45 ± 5	140 ± 14
SOUND OUTPUT (dB)	≥75	≥85	≥85
RESONANT FREQUENCY (Hz)	2400		
WORKING TEMPERATURE (°C)	-25.....+70		
STORAGE TEMPERATURE (°C)	-30.....+85		
WEIGHT (g)	2		

Value applying rated voltage (resonant frequency, square wave)

Value applying (Resonant Frequency, Sine wave, Measuring Current 60 μA)

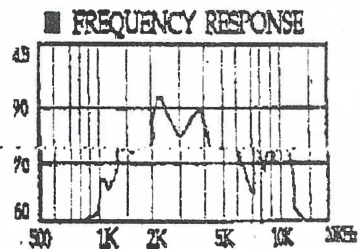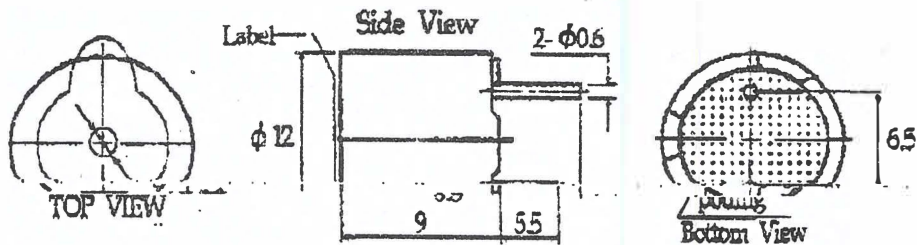

NOTE:

THE FREQUENCY CURVE AT 15VOLTAGE
DISTANCE BETWEEN 10 CM.