

Distributed by:






[www.Jameco.com](http://www.Jameco.com) ♦ 1-800-831-4242

The content and copyrights of the attached material are the property of its owner.

Jameco Part Number 232047  
(MD5-2445)

**NICHIBO** DC MOTOR

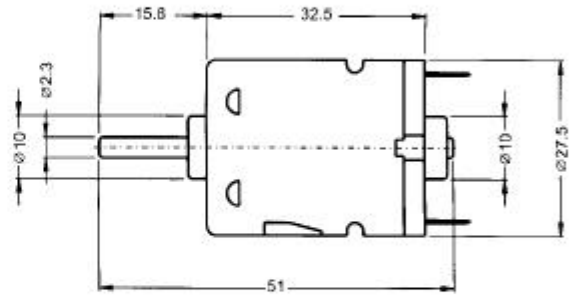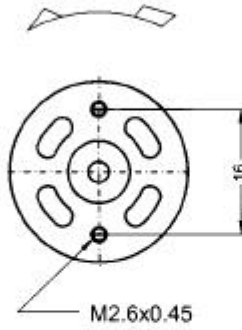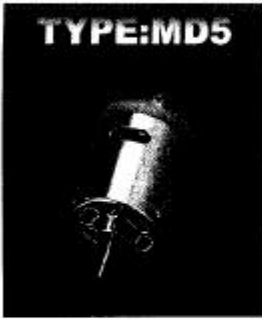

代表的用途：吹風機  
Typical Application : Blow Dryer

WEIGHT : 50g(APPROX)

MODEL	VOLTAGE		NO LOAD		AT MAXIMUM EFFICIENCY					STALL	
	OPERATING RANGE	NOMNAL	SPEED rpm	CURRENT A	SPEED rpm	CURRENT A	TORQUE g-cm	OUTPUT W	EFF %	CURRENT A	TORQUE g-cm
MD5-2445	6.0 - 12.0	12.0V CONSTANT	24500	0.65	19850	2.05	79.70	16.23	65.98	8.75	420
MD5-2070	6.0 - 12.0	12.0V CONSTANT	15700	0.30	12150	1.20	62.24	7.76	54.06	4.09	275
MD5-1885	6.0 - 18.0	12.0V CONSTANT	12500	0.20	9820	0.74	53.50	5.39	60.73	2.70	250
MD5-12160	12.0 - 24.0	12.0V CONSTANT	5600	0.12	4000	0.30	34.29	1.41	39.10	0.75	120

