


.079"(2.00mm) pitch single row headers

CW203 Series

- * Poles: 2-20
- * Material: Insulator: NYLON UL94V-2
- * Contact: 0.64mm(.025") square pin, brass, tin plated 60u"
- * Mates with CH203 series housing

Specifications


- * Current rating: 2A AC, DC
- * Voltage rating: 250V AC, DC
- * Temperature range: -25°C~+85°C
- * Insulation resistance: 1,000MΩ min.
- * Withstand voltage: 800V AC/minute
- * Applicable PC board thickness: .063" (1.6mm)

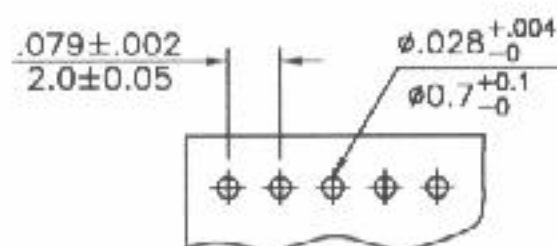

P.C. Board Layout


CW203S

Straight Angle

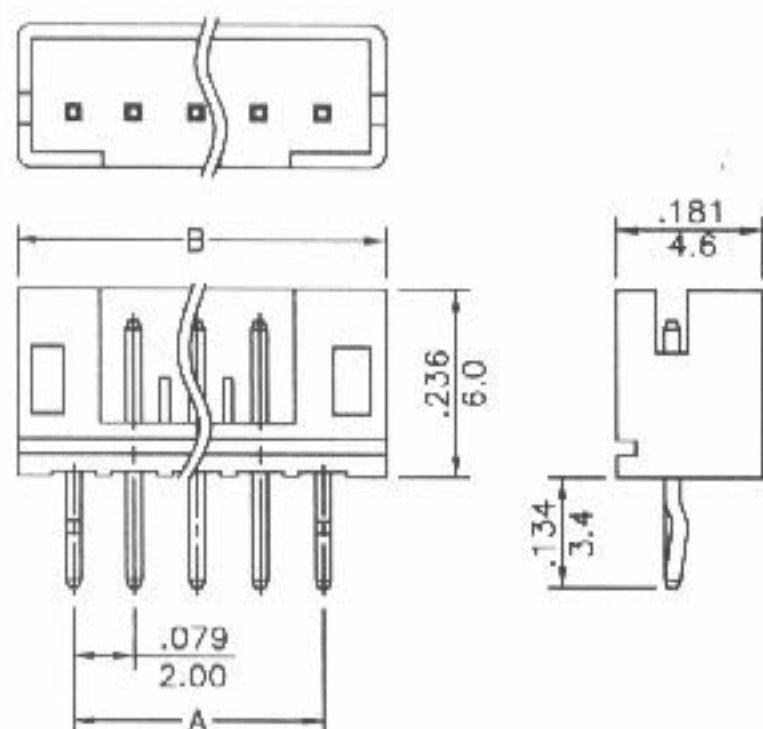

CW203R

Right Angle

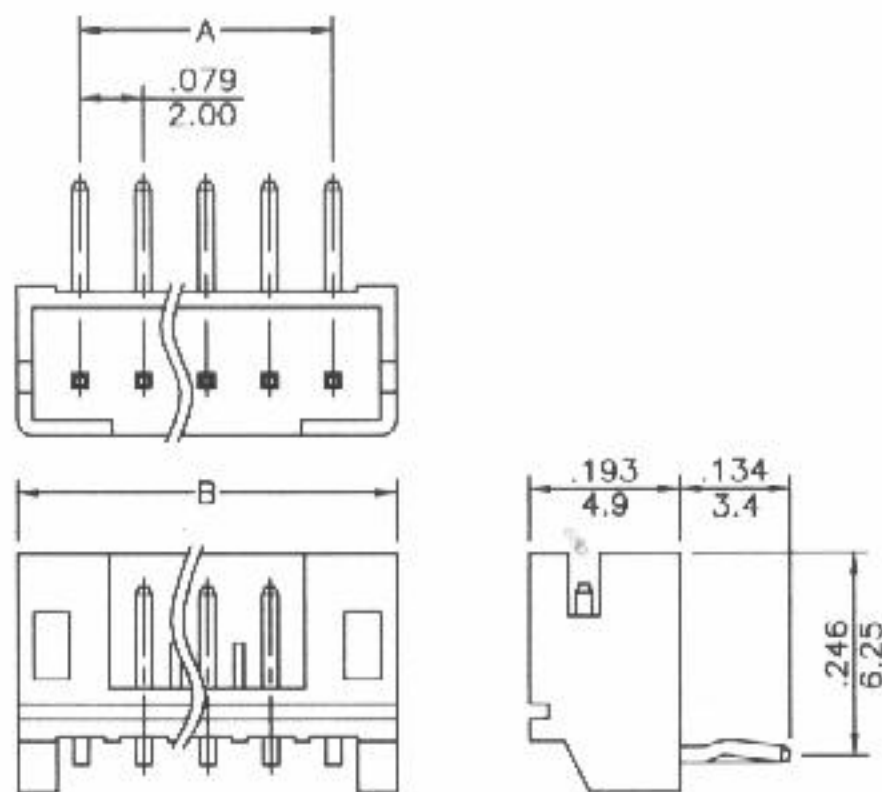

inches
mm

CIRCUITS	PART NO.	DIMENSION in.(mm)		CIRCUITS	PART NO.	DIMENSION in.(mm)	
		A	B			A	B
2	CW203X-02	0.079(2.00)	0.236(6.0)	12	CW203X-12	0.866(22.00)	1.024(26.0)
3	CW203X-03	0.157(4.00)	0.315(8.0)	13	CW203X-13	0.945(24.00)	1.102(28.0)
4	CW203X-04	0.236(6.00)	0.394(10.0)	14	CW203X-14	1.024(26.00)	1.181(30.0)
5	CW203X-05	0.315(8.00)	0.472(12.0)	15	CW203X-15	1.102(28.00)	1.260(32.0)
6	CW203X-06	0.394(10.00)	0.551(14.0)	16	CW203X-16	1.181(30.00)	1.339(34.0)
7	CW203X-07	0.472(12.00)	0.630(16.0)	17	CW203X-17	1.260(32.00)	1.418(36.0)
8	CW203X-08	0.551(14.00)	0.709(18.0)	18	CW203X-18	1.339(34.00)	1.496(38.0)
9	CW203X-09	0.630(16.00)	0.787(20.0)	19	CW203X-19	1.418(36.00)	1.575(40.0)
10	CW203X-10	0.709(18.00)	0.866(22.0)	20	CW203X-20	1.496(38.00)	1.654(42.0)
11	CW203X-11	0.787(20.00)	0.945(24.0)				