

Distributed by:

**JAMECO**<sup>®</sup>  
ELECTRONICS

**www.Jameco.com ♦ 1-800-831-4242**

The content and copyrights of the attached  
material are the property of its owner.

Jameco Part Number 236187

### Standard Housings — Wire-to-Board


#### Housings

##### Material:


UL94V-0 rated, nylon, white

##### Notes:

1. Accepts either .045 [1.14] square or round posts. Housings mate with flat and friction lock headers, or staked posts on .156 [3.96] centers.
2. Housings without ramp, with polarizing tab, available upon request. Minimums may apply.
3. Recommend contact:  
Part No. 640252 for 1 thru 12 positions; Part No. 350980 for 13 thru 24 positions; Part No. 770476 for 1 thru 24 positions.
4. These parts are End-to-End stackable.

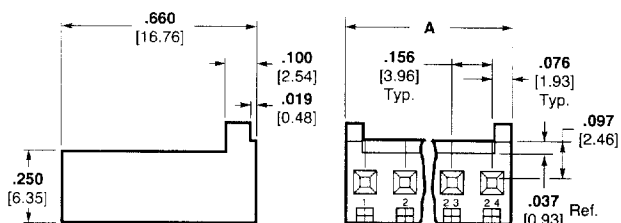

With Locking Ramp/With Polarizing Tabs

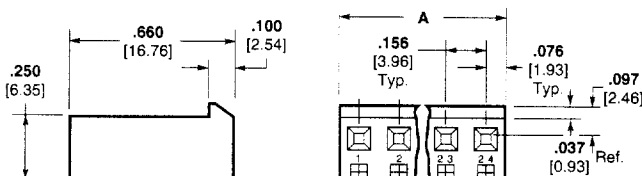


With Locking Ramp/Without Polarizing Tabs

For contacts, see page 2215.

For mateability options, see matrix on page 2214.

For mating half visuals, for connectors with locking ramp, see pages 2207 thru 2210 (2208 and 2209 Front Bend Headers only.)

For mating half visuals, for connectors without locking ramp, see pages 2207 thru 2210.

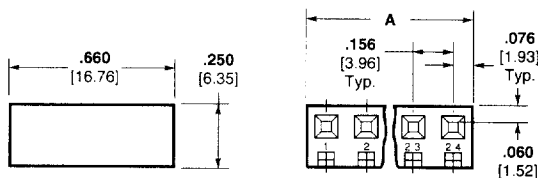

Without Locking Ramp/Without Polarizing Tabs

No. of Positions	Dim. A	With Ramp/With Tabs	With Ramp/Without Tabs	Without Ramp/Without Tabs
1	.152 3.86	—	640250-1	640251-1
2	.308 7.82	770849-2	640250-2	640251-2
3	.465 11.81	770849-3	640250-3	640251-3
4	.621 15.77	770849-4	640250-4	640251-4
5	.777 19.74	770849-5	640250-5	640251-5
6	.933 23.70	770849-6	640250-6	640251-6
7	1.090 27.69	770849-7	640250-7	640251-7
8	1.246 31.65	770849-8	640250-8	640251-8
9	1.402 35.61	770849-9	640250-9	640251-9
10	1.558 39.57	1-770849-0	1-640250-0	1-640251-0
11	1.715 43.56	1-770849-1	1-640250-1	1-640251-1
12	1.871 47.52	1-770849-2	1-640250-2	1-640251-2

No. of Positions	Dim. A	With Ramp/With Tabs	With Ramp/Without Tabs	Without Ramp/Without Tabs
13	2.027 51.49	1-770849-3	1-640250-3	1-640251-3
14	2.183 55.45	1-770849-4	1-640250-4	1-640251-4
15	2.340 59.44	1-770849-5	1-640250-5	1-640251-5
16	2.496 63.40	1-770849-6	1-640250-6	1-640251-6
17	2.652 67.36	1-770849-7	1-640250-7	1-640251-7
18	2.808 71.32	1-770849-8	1-640250-8	1-640251-8
19	2.965 75.31	1-770849-9	1-640250-9	1-640251-9
20	3.121 79.27	2-770849-0	2-640250-0	2-640251-0
21	3.277 83.24	2-770849-1	2-640250-1	2-640251-1
22	3.433 87.20	2-770849-2	2-640250-2	2-640251-2
23	3.590 91.19	2-770849-3	2-640250-3	2-640251-3
24	3.746 95.15	2-770849-4	2-640250-4	2-640251-4

**Note:** Not for use with LID contacts, shown on page 2217.

For complete product information, order Catalog 82056