

Distributed by:

**JAMECO**<sup>®</sup>  
ELECTRONICS

**www.Jameco.com ♦ 1-800-831-4242**

The content and copyrights of the attached  
material are the property of its owner.

Jameco Part Number 237607



# Step Motors

57BYGH001

Step Angle-----1.8° ± 5%  
 Insulation Resistant-----500V DC 100MΩ Min  
 Operating Temp Range----- -10°C ~ +40°C  
 Storing Temp Range----- -30°C ~ +80°C  
 Temperature Rise ----- 80°C Max



P/N	MFG Model	No of Phase	Voltage (V)	Current (A)	Resistance (Ohm)	Inductance (mH)	Holding Torque (Kg-cm)	Detent Torque (g-cm)	Length L0 (mm)	Length L1 (mm)
237607	57BYGH001	4	5	1.0	5.0	5.0	4.0	220	41	21

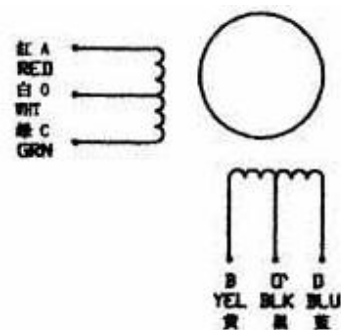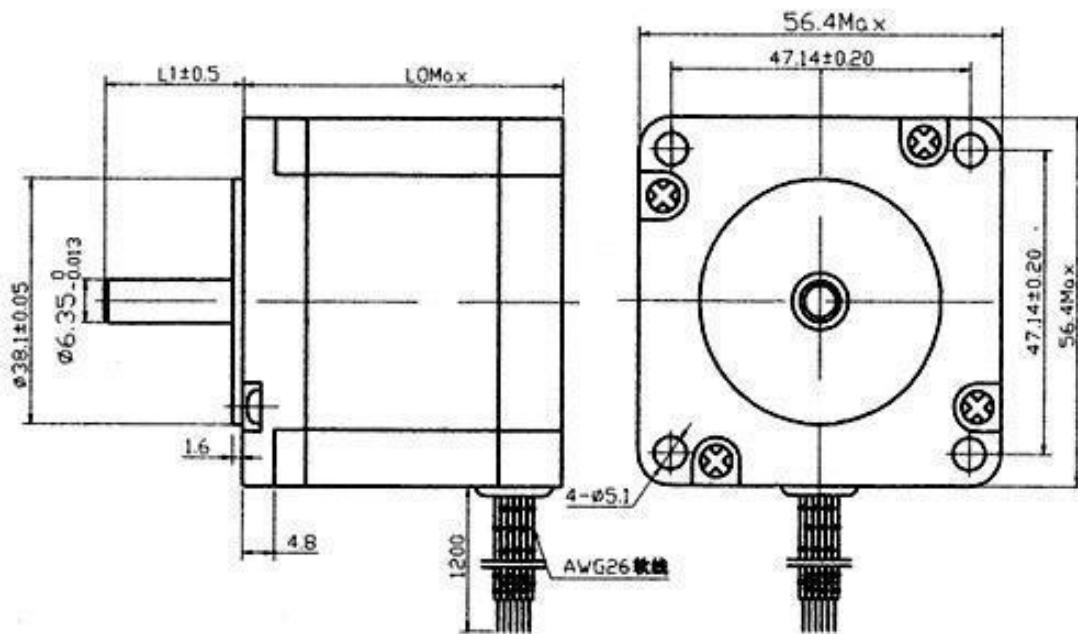

Sinotech Shanghai  
 Room 1404 1759 North Zhongshan Road, Putuo District,  
 Shanghai, China