


Distributed by:

**JAMECO<sup>®</sup>**  
**ELECTRONICS**

[www.Jameco.com](http://www.Jameco.com) ♦ 1-800-831-4242


The content and copyrights of the attached  
material are the property of its owner.

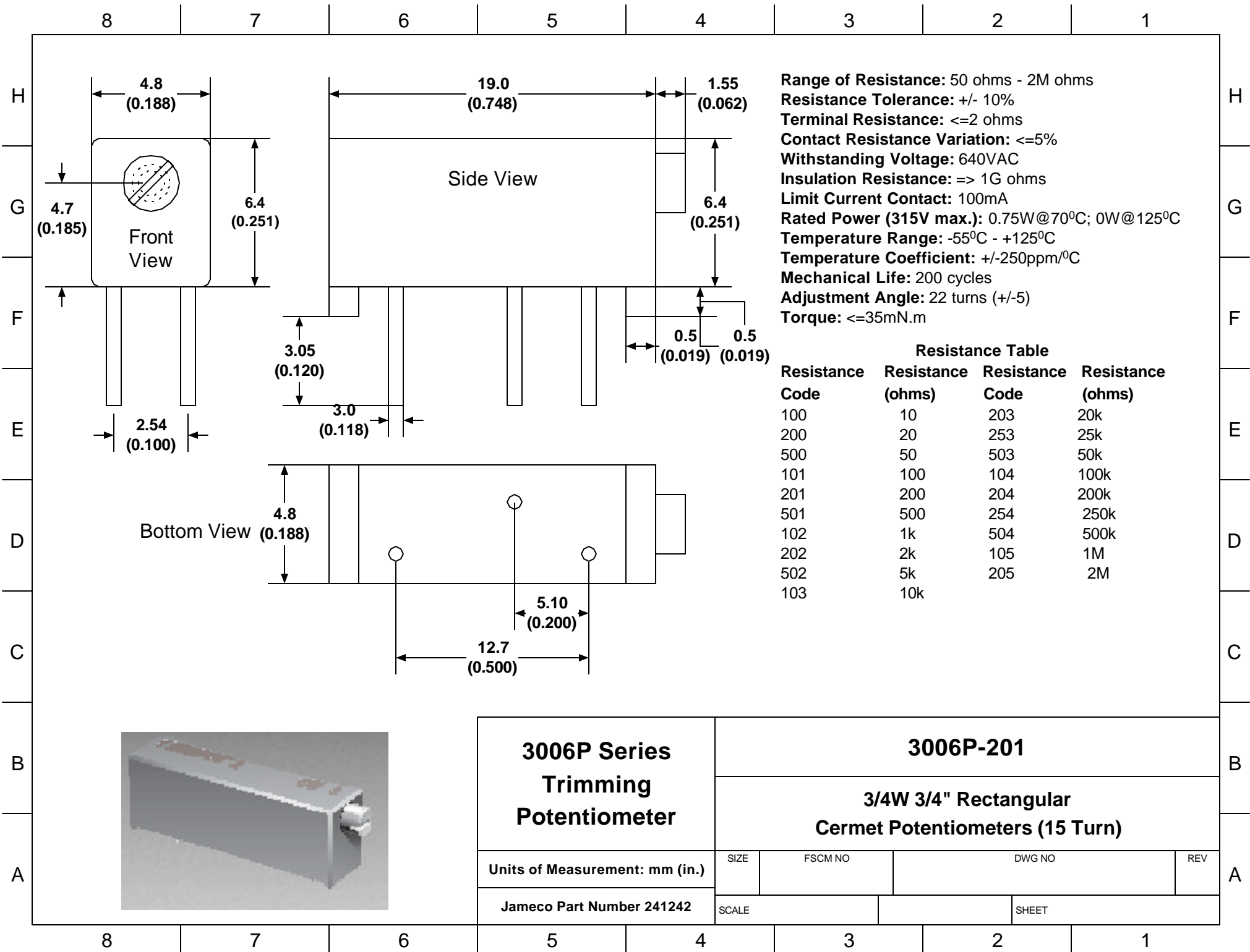

**Range of Resistance:** 50 ohms - 2M ohms  
**Resistance Tolerance:** +/- 10%  
**Terminal Resistance:** <=2 ohms  
**Contact Resistance Variation:** <=5%  
**Withstanding Voltage:** 640VAC  
**Insulation Resistance:** => 1G ohms  
**Limit Current Contact:** 100mA  
**Rated Power (315V max.):** 0.75W@70°C; 0W@125°C  
**Temperature Range:** -55°C - +125°C  
**Temperature Coefficient:** +/-250ppm/°C  
**Mechanical Life:** 200 cycles  
**Adjustment Angle:** 22 turns (+/-5)  
**Torque:** <=35mN.m

**Resistance Table**

Resistance Code	Resistance (ohms)	Resistance Code	Resistance (ohms)
100	10	203	20k
200	20	253	25k
500	50	503	50k
101	100	104	100k
201	200	204	200k
501	500	254	250k
102	1k	504	500k
202	2k	105	1M
502	5k	205	2M
103	10k		

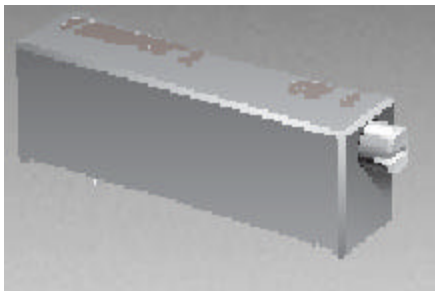

<b>3006P Series Trimming Potentiometer</b>	<b>3006P-201</b>		
	<b>3/4W 3/4" Rectangular Cermet Potentiometers (15 Turn)</b>		
Units of Measurement: mm (in.)	SIZE	FSCM NO	DWG NO
Jameco Part Number 241242	SCALE	SHEET	
		REV	