


Distributed by:

JAMECO[®]
ELECTRONICS

www.Jameco.com ♦ 1-800-831-4242


The content and copyrights of the attached
material are the property of its owner.

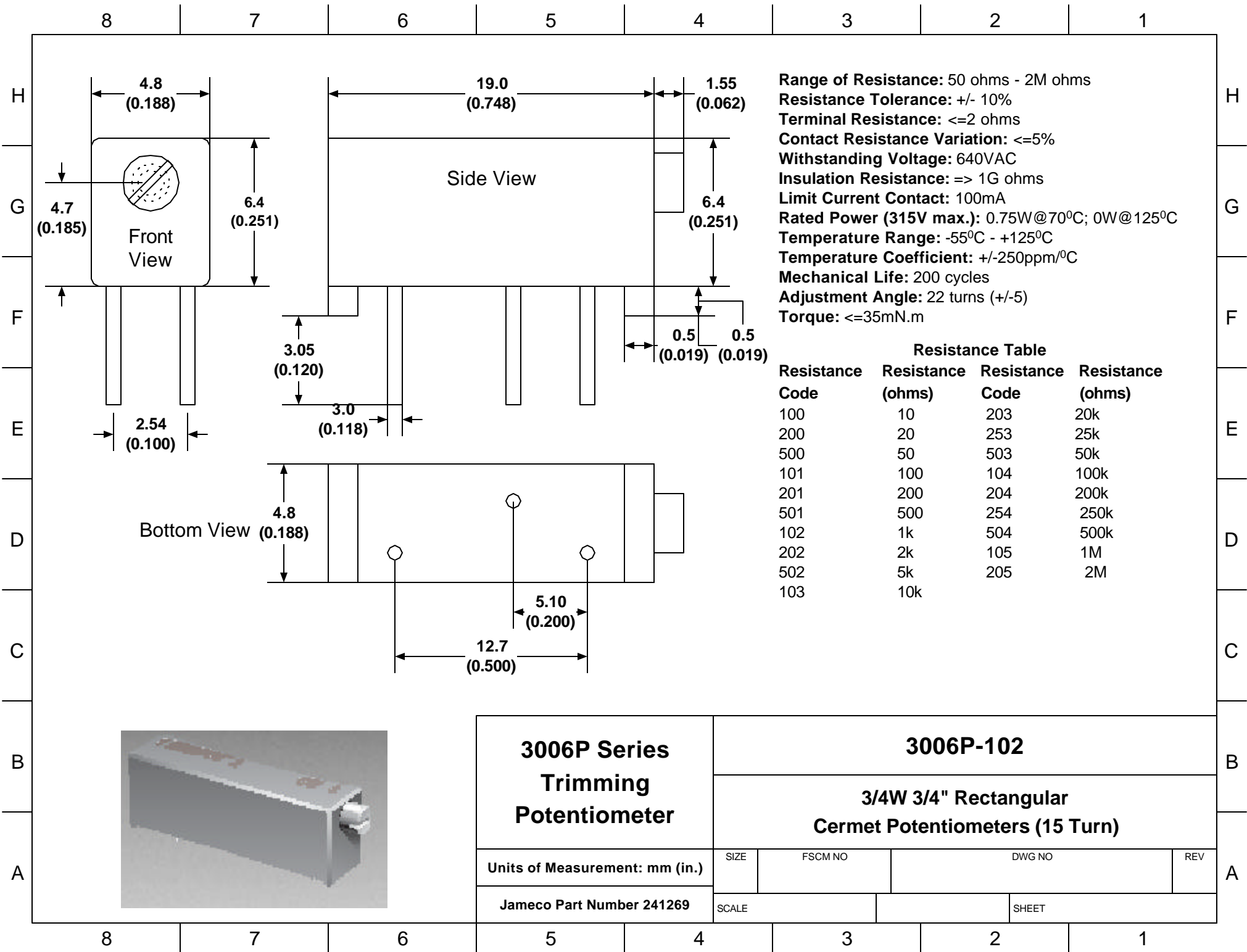

Range of Resistance: 50 ohms - 2M ohms
Resistance Tolerance: +/- 10%
Terminal Resistance: <=2 ohms
Contact Resistance Variation: <=5%
Withstanding Voltage: 640VAC
Insulation Resistance: => 1G ohms
Limit Current Contact: 100mA
Rated Power (315V max.): 0.75W@70°C; 0W@125°C
Temperature Range: -55°C - +125°C
Temperature Coefficient: +/-250ppm/°C
Mechanical Life: 200 cycles
Adjustment Angle: 22 turns (+/-5)
Torque: <=35mN.m

Resistance Table

Resistance Code	Resistance (ohms)	Resistance Code	Resistance (ohms)
100	10	203	20k
200	20	253	25k
500	50	503	50k
101	100	104	100k
201	200	204	200k
501	500	254	250k
102	1k	504	500k
202	2k	105	1M
502	5k	205	2M
103	10k		

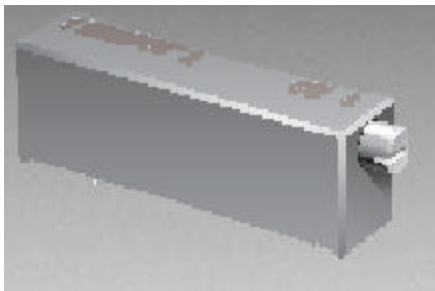

3006P Series Trimming Potentiometer	3006P-102		
	3/4W 3/4" Rectangular Cermet Potentiometers (15 Turn)		
Units of Measurement: mm (in.)	SIZE	FSCM NO	DWG NO
Jameco Part Number 241269	SCALE	SHEET	
		REV	