

|    |             |   |
|----|-------------|---|
| 1  | CL-106-63   | 1 |
| 2  | CL-106-06   | 1 |
| 3  | CL-107-42   | 1 |
| 4  | CL-107-04   | 1 |
| 5  | CL-102-31   | 1 |
| 6  | CL-102-03   | 1 |
| 7  | CL-507-4T10 | 1 |
| 8  | CL-507-4T15 | 1 |
| 9  | CL-507-310  | 1 |
| 10 | CL-507-311  | 1 |
| 11 | CL-104-1.5  | 1 |
| 12 | CL-104-1.52 | 1 |
| 13 | GTE-109     | 1 |
| 14 | GWH-106     | 1 |
| 15 | TOR-136     | 1 |
| 16 | GSR-124     | 1 |
| 17 | GCP-043     | 1 |
| 18 | GCP-046     | 1 |
| 19 | WS-001      | 1 |
| 20 | GPL-104     | 1 |
| 21 | GPL-102     | 1 |
| 22 | GPL-101     | 1 |
| 23 | GPL-103     | 1 |

## 100 PIECE Pro-Tec Tool Kit

### • Features:


- The heavy duty tool case includes 2 locks, a durable handle and tool alllets.
- Use it for building, repairing and general maintenance.
- This tool kit is ideal for field repair technicians, the do-it-yourselfer or anyone who needs to keep a set of useful tools with them while traveling.

### • Kit Includes:

- 7 PCS Folding HEX Key Set (1.5, 2, 2.5, 3, 4, 5, 6mm).
- DIP IC Extractor. • 3 Prong Holder. • Fine Tip Stainless Steel Tweezer #00 Non-magnetic. • 5 PCS Needle File Set. • 10 PCS Electronic Open-End / Box Wrench (4, 4.5, 5, 5.5, 6, 7, 8, 9, 10, 11mm).
- Alignment Screwdriver. • 250g Claw Hammer. • Inspection Mirror with Telescoping. • 30ft. PVC Electrical Insulation Tape Black Color. • Tape Measure ABS Case with Rubber Jacket 3M/10ft. • Plastic Fliptop Box. • 4 1/2" Diagonal Plier. • 4 3/4" Long Nose Plier. • 5 3/4" Bent Nose Plier. • 5" Flat Nose Plier. • 6" Side Cutting Plier. • 6" Long Nose Plier. • 6" Slip Joint Plier. • 8" Combination Plier. • 9" Wire Stripper/Crimper for Wire 0.75~6mm. • 6 PCS Assorted Precision Screwdriver Set. • Digital Multimeter. • Solder Core with LEAD FREE. • 7" Brush-Knife. • 7" Hook-Scraper. • 7" Fork-Spike. • Cleaning Brushes. • Plastic Desolder Pump. • 30W Soldering Iron. • 6" Wire Stripper Plier for Wire 0.6~2.6mm/22~10AWG. • 29 PCS 1/4" DR.Socket Wrench Set. • Wrist Strap Elastic Light Blue Color 6ft. PU Coiled. • Aluminum Flashlight Red Color (Dia.24mm x 152mmL).
- Super Holding Cushion Grip Screwdrivers:
  - ▶ #3 x 150mm, #2 x 100mm, #1 x 100mm.
  - ▶ #8 x 150mm, 6 x 100mm, 5 x 100mm.
- 6" Adjustable Wrench Chrome plated Insulation Handle.
- Mini Drill with Drill Bits. • Mini Hobby Vise Aluminum jaw width 2.4" (60mm). • Heavy Duty Tool Case with Protected Corner.

## GOLDSUN ELECTRONICS CO., LTD.

|             |        |  |  |             |  |         |  |   |
|-------------|--------|--|--|-------------|--|---------|--|---|
| JAMECO NO.  |        | 242851                                       |  | GOLDSUN NO. |  | GTK-700 |  |   |
| Description |        | LARGE COMPUTER/ELECTRONIC TOOL KIT (GTK-700) |  |             |  | Rev.    |  | 1 |
| UNIT:       | SCALE: | SHEET 1 OF 1                                 |  | CAS No:     |  | ERN No: |  |   |
| mm          |        |  |  |             |  |         |  |   |

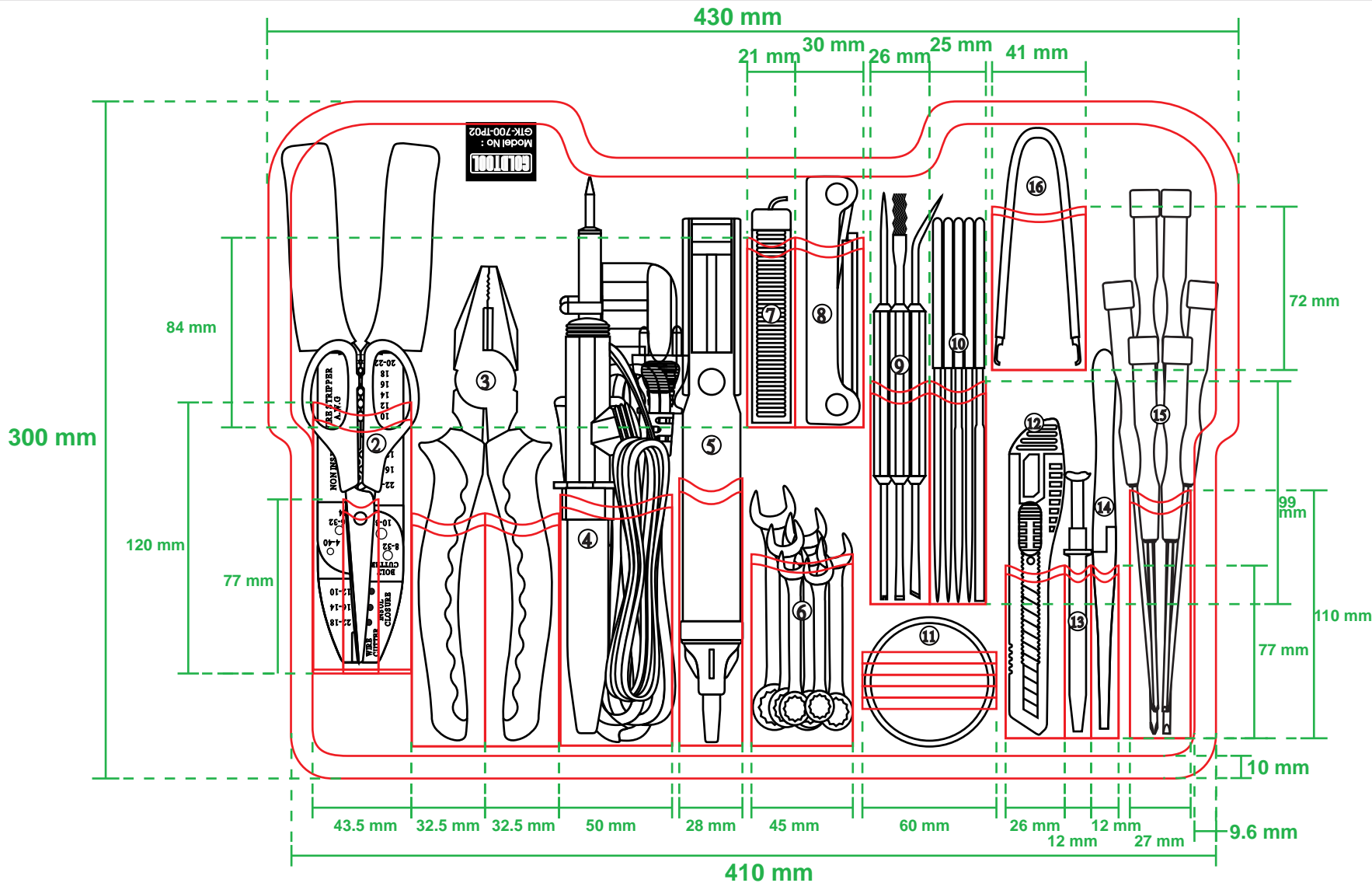

|    |             |   |
|----|-------------|---|
| 1  | GRK-40N     | 1 |
| 2  | GKN-601     | 1 |
| 3  | GPL-688     | 1 |
| 4  | GSR-213A(B) | 1 |
| 5  | GSR-326     | 1 |
| 6  | GCP-013M    | 1 |
| 7  | GSR-101B    | 1 |
| 8  | FHM-307     | 1 |
| 9  | GSR-107ABC  | 1 |
| 10 | GCP-012     | 1 |
| 11 | GMG-551     | 1 |
| 12 | GKN-102     | 1 |
| 13 | GCP-003     | 1 |
| 14 | GCP-008     | 1 |
| 15 | GSD-503     | 1 |
| 16 | GCP-002     | 1 |
| 17 |             |   |
| 18 |             |   |
| 19 |             |   |
| 20 |             |   |
| 21 |             |   |
| 22 |             |   |
| 23 |             |   |

## 95 PIECE Pro-Tec Tool Kit

### • Features:

- The heavy duty tool case includes 2 locks, a durable handle and tool alllets.
- Use it for building, repairing and general maintenance.
- This tool kit is ideal for field repair technicians, the do-it-yourselfer or anyone who needs to keep a set of useful tools with them while traveling.

### • Kit Includes:

- 7 PCS Folding HEX Key Set (1.5, 2, 2.5, 3, 4, 5, 6mm).
- DIP IC Extractor.
- 3 Prong Holder.
- Fine Tip Stainless Steel Tweezer #00 Non-magnetic.
- 5 PCS Needle File Set.
- 10 PCS Electronic Open-End / Box Wrench (4, 4.5, 5, 5.5, 6, 7, 8, 9, 10, 11mm).
- Alignment Screwdriver.
- 250g Claw Hammer.
- Inspection Mirror with Telescoping.
- 30ft. PVC Electrical Insulation Tape Black Color.
- Tape Measure ABS Case with Rubber Jacket 3M/10ft.
- Plastic Fliptop Box.
- 4 1/2" Diagonal Plier.
- 4 3/4" Long Nose Plier.
- 5 3/4" Bent Nose Plier.
- 5" Flat Nose Plier.
- 6" Side Cutting Plier.
- 6" Long Nose Plier.
- 6" Slip Joint Plier.
- 8" Combination Plier.
- 9" Wire Stripper/Crimper for Wire 0.75~6mm.
- 6 PCS Assorted Precision Screwdriver Set.
- Digital Multimeter.
- Solder Core with LEAD FREE.
- 7" Brush-Knife.
- 7" Hook-Scraper.
- 7" Fork-Spike.
- Cleaning Brushes.
- Plastic Desolder Pump.
- 30W Soldering Iron.
- 6" Wire Stripper Plier for Wire 0.6~2.6mm/22~10AWG.
- 29 PCS 1/4" DR.Socket Wrench Set.
- Wrist Strap Elastic Light Blue Color 6ft. PU Coiled.
- Aluminum Flashlight Red Color (Dia.24mm x 152mmL).
- Super Holding Cushion Grip Screwdrivers:
  - ▶ #3 x 150mm, #2 x 100mm, #1 x 100mm.
  - ▶ #8 x 150mm, 6 x 100mm, 5 x 100mm.
- 6" Adjustable Wrench Chrome plated Insulation Handle.
- Mini Drill with Drill Bits.
- Mini Hobby Vise Aluminum jaw width 2.4" (60mm).
- Heavy Duty Tool Case with Protected Corner.

## GOLDSUN ELECTRONICS CO., LTD.

|             |        |  |  |             |  |         |  |   |  |
|-------------|--------|--|--|-------------|--|---------|--|---|--|
| JAMECO NO.  |        | 242851                                       |  | GOLDSUN NO. |  | GTK-700 |  |   |  |
| Description |        | LARGE COMPUTER/ELECTRONIC TOOL KIT (GTK-700) |  |             |  | Rev.    |  | 1 |  |
| UNIT:       | SCALE: | SHEET 1 OF 1                                 |  | CAS No:     |  | ERN No: |  |   |  |
| mm          |        |  |  |             |  |         |  |   |  |