



SPECIFICATIONS SHEET

PRODUCT TYPE : MECHANICAL BUZZER

PRODUCT SERIES : DB-E638

DESCRIPTION : MC BUZZER SINGLE 9VDC L/W ABS SP RoHS

COLOR : BLACK

ELECTRICAL SPECIFICATIONS


MODEL NO.	63S1090LF - LA	
OPERATING VOLTAGE RANGE (VDC)	6.0 ~ 12.0	
RATED VOLTAGE (VDC)	9	
* MAX. RATED CURRENT (mA)	25	
* MIN. SOUND OUTPUT (dBA/ 20 cm)	75	
* FREQUENCY (Hz)	400 +/- 100	
TONE NATURE	SINGLE	
OPERATING TEMPERATURE (° C)	-10 ~ +60	
TERMINAL	LEADWIRE (UL1095 , AWG#26)	
HOUSING MATERIAL	ABS	
WEIGHT (g)	10.0	

* Value applying at rated voltage


DIMENSIONS

UNIT : mm

TOP VIEW

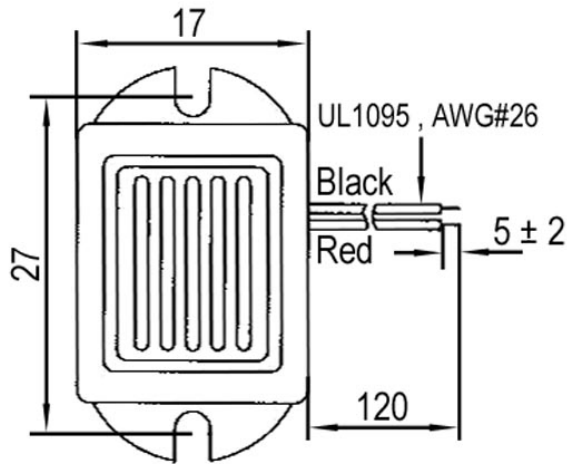

SIDE VIEW

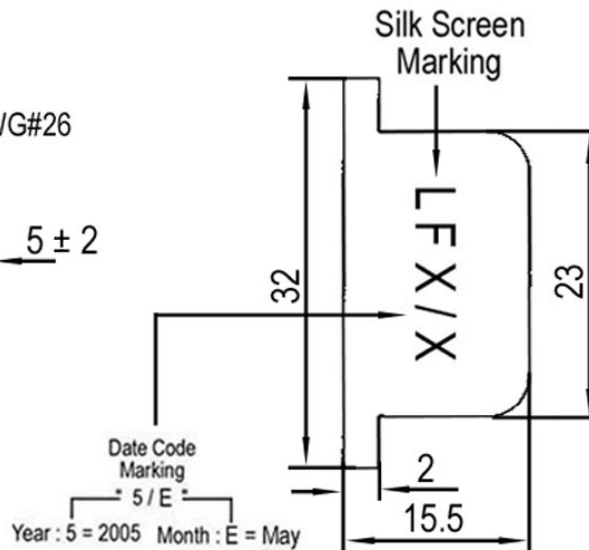

Approved By : 
Date : 06-Jun-2006

Prepared By : 
Date : 06-Jun-2006

Modify :	Date :	By :