




80X80X38mm




General Specifications

Airflow	16~30 CFM
Static Pressure	0.10~0.24 Inch-H ₂ O
Housing	Die Cast Zinc Painted Black Or Natural Color
Motor Type	Shaded Pole, Impedance Protected
Connecting	Terminal & Wire Leads

Dimensions:mm

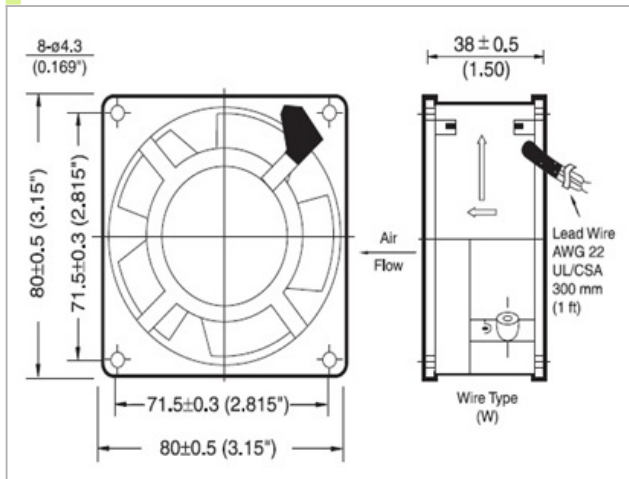

Performance

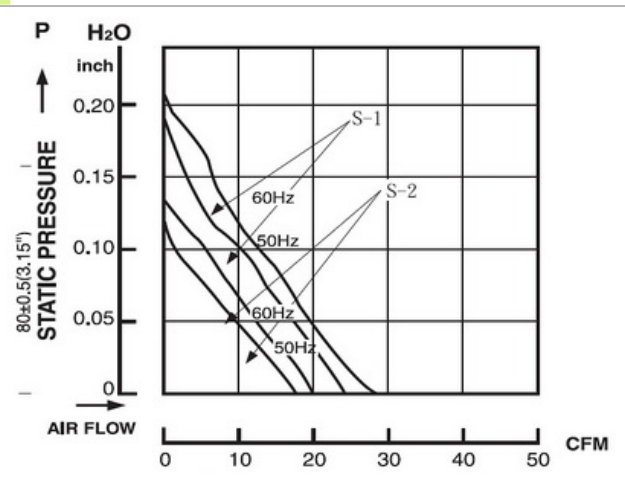

Specifications

Model NO.	Bearing	Rated Voltage	Frequency	Speed	Airflow	Static Pressure	Current	Power	Noise
		VAC	HZ	RPM	CFM	Inch-H ₂ O	A	W	dBA
GA1083HBL	2BALL	110/120	50/60	2300/2700	26/30	0.17/0.24	0.14/0.12	13/12	30/35
GA1083HSL	SLEEVE	110/120	50/60	2300/2700	26/30	0.17/0.24	0.14/0.12	13/12	30/35
GA2083HBL	2BALL	220/240	50/60	2300/2700	26/30	0.17/0.24	0.10/0.08	13/12	30/35
GA2083HSL	SLEEVE	220/240	50/60	2300/2700	26/30	0.17/0.24	0.10/0.08	13/12	30/35
GA1083MBL	2BALL	110/120	50/60	2000/2300	21/23	0.14/0.15	0.12/0.10	10/9	24/27
GA2083MBL	2BALL	220/240	50/60	2000/2300	21/23	0.14/0.15	0.08/0.06	10/9	24/27
GA1083LBL	2BALL	110/120	50/60	1700/1900	17/16	0.12/0.10	0.08/0.06	6/5	21/23
GA2083LBL	2BALL	220/240	50/60	1700/1900	17/16	0.12/0.10	0.05/0.04	6/5	21/23