

Distributed by:

JAMECO[®]
ELECTRONICS

www.Jameco.com ♦ 1-800-831-4242


The content and copyrights of the attached
material are the property of its owner.

Jameco Part Number 254044


3299-W-102
 Model产品型号
 Style引出方式
 Code阻值代码




3362P

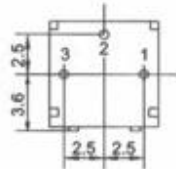

3362P 型

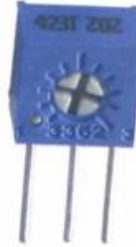

3362W

 

3362W 型

| Series | P/N | MFG | Resistance (Ohms) | Characteristics | | | |
|--------|--------|-------------|-------------------|-----------------------------|------------------------------|-----------------------|--------------------------|
| | | | | Total Mechanical Travel | 250°±10° | Starting Torque | ≤20mN.m |
| P | 253982 | 3362P-1-102 | 1,000 | Withstand Voltage | 101.3KPa 500V 8.5KPa 315V | Insulation Resistance | R1 ≥ 1G Ω |
| | 254036 | 3362P-1-104 | 100,000 | | | | |
| | 254028 | 3362P-1-503 | 50,000 | | | | |
| | 254044 | 3362P-1-504 | 500,000 | | | | |
| W | 254175 | 3362W-1-102 | 1,000 | Effective Electrical Travel | 210°±10° | Standard Packaging | 50pcs/tube |
| | 254204 | 3362W-1-103 | 10,000 | | | | |
| | 254247 | 3362W-1-104 | 100,000 | | | | |
| | | | | Rated Power | +70°C 0.5W +125°C 0W | Mechanical Endurance | 200 cycles ΔR ≤ ±10%R |