


Distributed by:

**JAMECO<sup>®</sup>**  
**ELECTRONICS**

[www.Jameco.com](http://www.Jameco.com) ♦ 1-800-831-4242

The content and copyrights of the attached  
material are the property of its owner.

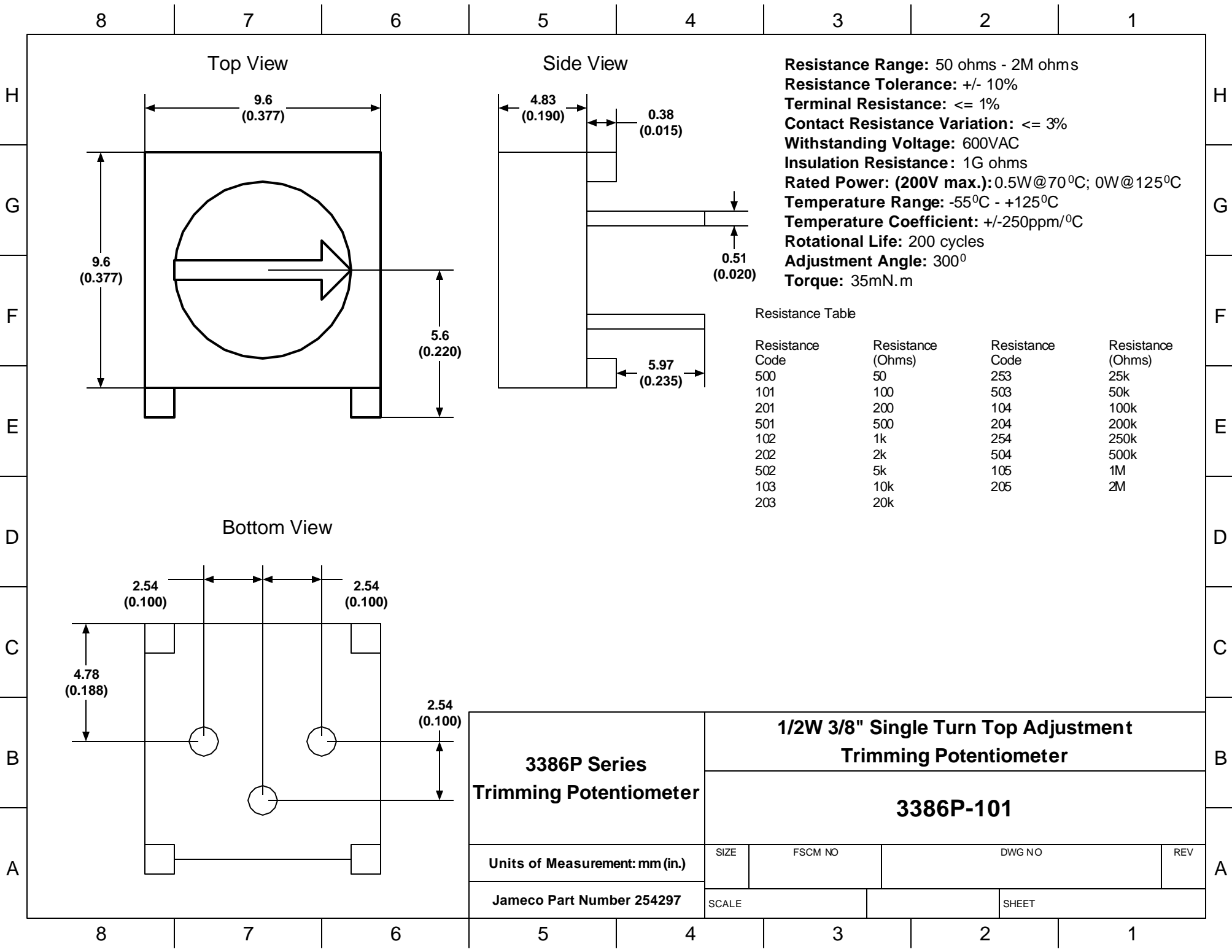

**Resistance Range:** 50 ohms - 2M ohms  
**Resistance Tolerance:** +/- 10%  
**Terminal Resistance:** <= 1%  
**Contact Resistance Variation:** <= 3%  
**Withstanding Voltage:** 600VAC  
**Insulation Resistance:** 1G ohms  
**Rated Power: (200V max.):** 0.5W@70°C; 0W@125°C  
**Temperature Range:** -55°C - +125°C  
**Temperature Coefficient:** +/-250ppm/°C  
**Rotational Life:** 200 cycles  
**Adjustment Angle:** 300°  
**Torque:** 35mN.m

<b>3386P Series Trimming Potentiometer</b>	<b>1/2W 3/8" Single Turn Top Adjustment Trimming Potentiometer</b>		
	<b>3386P-101</b>		
<b>Units of Measurement: mm (in.)</b>	SIZE	FSCM NO	DWG NO
<b>Jameco Part Number 254297</b>	SCALE	SHEET	

H  
G  
F  
E  
D  
C  
B  
A