


Distributed by:

JAMECO[®]
ELECTRONICS

www.Jameco.com ♦ 1-800-831-4242

The content and copyrights of the attached
material are the property of its owner.

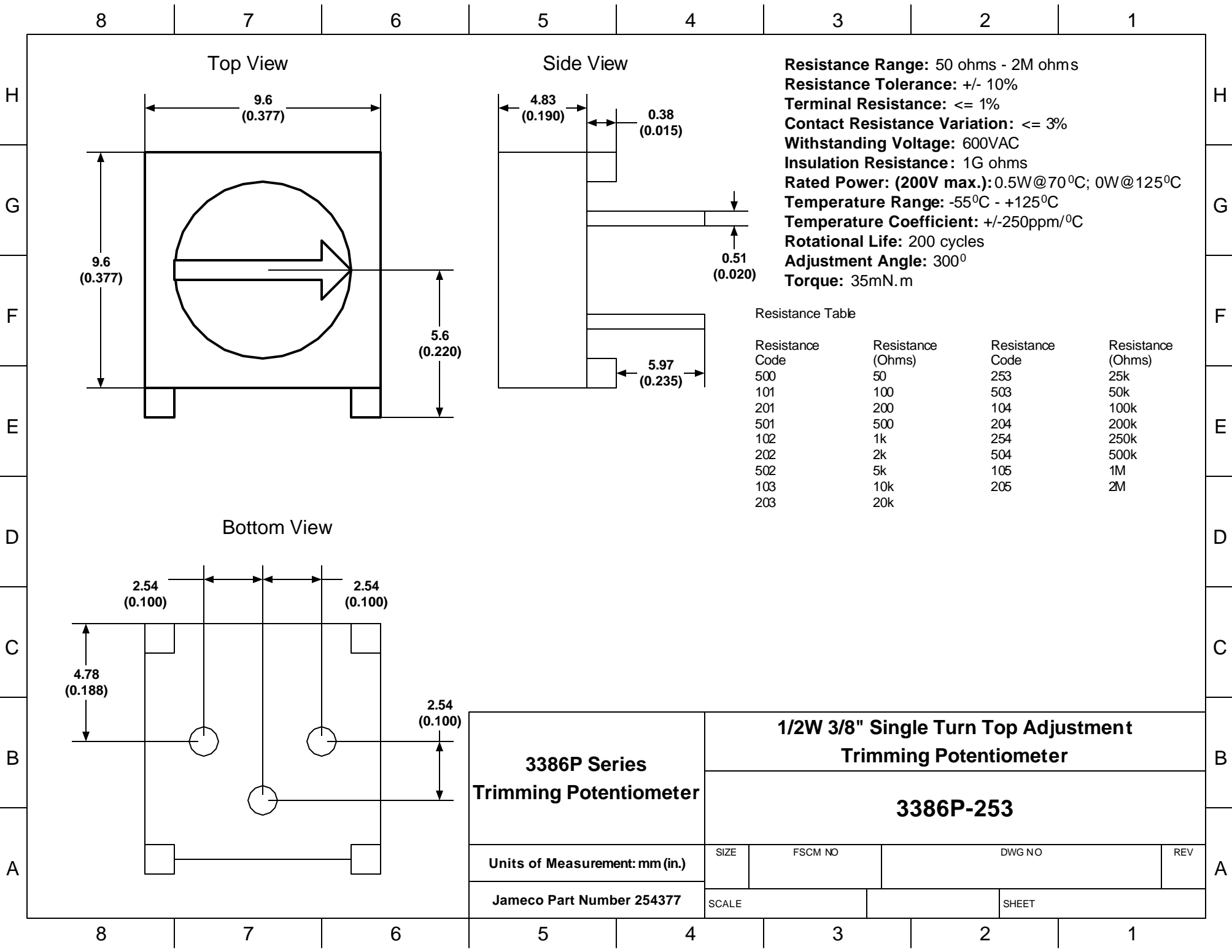

Resistance Range: 50 ohms - 2M ohms
Resistance Tolerance: +/- 10%
Terminal Resistance: <= 1%
Contact Resistance Variation: <= 3%
Withstanding Voltage: 600VAC
Insulation Resistance: 1G ohms
Rated Power: (200V max.): 0.5W@70°C; 0W@125°C
Temperature Range: -55°C - +125°C
Temperature Coefficient: +/-250ppm/°C
Rotational Life: 200 cycles
Adjustment Angle: 300°
Torque: 35mN.m

3386P Series Trimming Potentiometer	1/2W 3/8" Single Turn Top Adjustment Trimming Potentiometer		
	3386P-253		
Units of Measurement: mm (in.)	SIZE	FSCM NO	DWG NO
Jameco Part Number 254377	SCALE	SHEET	

H
G
F
E
D
C
B
A