
 


P.C. MOUNTING

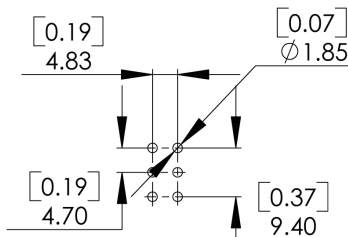

Schematic



| Model No. | Switching Position | | |
|-----------|--------------------|-------------|-------------|
| T201 | ON | NONE | ON |
| T202 | ON | NONE | (ON) |
| T203 | ON | OFF | ON |
| T204 | (ON) | OFF | (ON) |
| T205 | ON | OFF | (ON) |
| T206 | 2-3, 5-6 ON | 2-3, 5-6 ON | 2-1, 5-4 ON |

SPECIFICATIONS:

CONTACT RATING : 5 AMPS @ 120 V AC or 28 V DC.
 2 AMPS @ 250 V AC or 0.4VA AMPS @20 V AC or DC.
 ELECTRICAL LIFE : 6,000 make-and-break cycles at full load.
 CONTACT RESISTANCE : 10 mΩ max. initial @ 2-4 V DC.
 100 mA, for both silver and gold plated contacts.
 INSULATION RESISTANCE : 1,000 MΩ min.
 DIELECTRIC STRENGTH : 1,000 V RMS @ sea level.
 OPERATING TEMPERATURE : -30 °C to 130 °C

MATERIALS:

CASE : Diallyl phthalate (DAP)(UL-94V-0).
 ACTUATOR : ZINC ALLOY.
 BUSHING : ZINC ALLOY.
 HOUSING : Stainless steel.
 TERMINAL/CONTACT : Brass, with silver or gold plated.
 or gold over silver.
 SWITCH SUPPORT : Brass, tin plated.

GOLDSUN ELECTRONICS CO., LTD.

| | |
|---|------------------------------------|
| JAMECO NO. 26367-100(Bakelite) | GOLDSUN NO. T201T1B1A2QN |
| Description "MINI TOGGLE SWITCH ON-ON DPDT6P PCB TERMINAL 6A 125VAC" | |
| UNIT: mm | SCALE: SHEET 1 OF 1 |
| CAS No: ERN No: | |
| Rev. 1 | |